

Specification Sheet

Part Number: 151-03098


4-way opening allows cable ties to be installed parallel or perpendicular to bundles.

The high-heat, high-bond adhesive is ideal for outdoor applications.

Two predrilled holes extend mounting options and solutions.

Extended adhesive liner is easy to remove quickly.

Low fire hazard materials comply with stringent NFPA 130 safety standards and improve opportunities to get product specified at the engineering stage of a project (excluding adhesive).

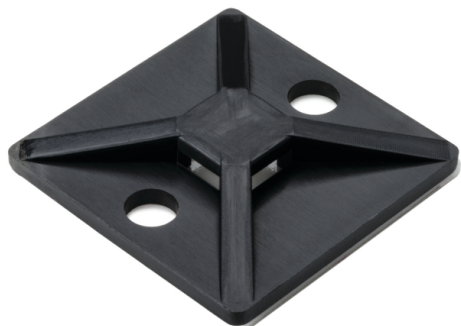

Adhesive Cable Tie Mount, 1.12" x 1.12", 0.18" Max Tie Width, 0.18" Hole Dia, PA666V0 T50, Black, 100/pkg

Article Number 151-03098

Type MB4A

Color Black (BK)

Quantity Per carton

Product Description MB4A adhesive mounts are for use with HellermannTyton T18 - T50 Series cable ties to provide stability when securing bundles. The high-heat, high-bond acrylic adhesive-backed mounts can be used to secure a bundle and have two predrilled holes to extend mounting options.

| | |
|-------------------------------------|---|
| Short Description | Adhesive Cable Tie Mount, 1.12" x 1.12", 0.18" Max Tie Width, 0.18" Hole Dia, PA666V0 T50, Black, 100/pkg |
| Global Part Name | MB4A-PA666V0-BK |
| Length L (Imperial) | 1.12 |
| Length L (Metric) | 28.5 |
| Fixation Method | Screw Mounting and Adhesive |
| Width W (Imperial) | 1.12 |
| Width W (Metric) | 28.5 |
| Cable Ties | T18 - T50 |
| Height H (Imperial) | 0.22 |
| Height H (Metric) | 5.6 |
| Cable Tie Width Max (Imperial) | 0.18 |
| Cable Tie Width Max (Metric) | 5.4 |
| Mounting Hole Diameter D (Imperial) | 0.18 |
| Mounting Hole Diameter D (Metric) | 4.6 mm |
| Mounting Hole Centers (Imperial) | 0.8 |

| | |
|------------------------------|--|
| Material | Polyamide 6.6/6, V0 (PA666V0) |
| Material Shortcut | PA666V0 |
| Adhesive | High heat high bond acrylate with base of acrylic foam |
| Flammability | UL 94 V-0 |
| Halogen Free | No |
| UV Resistant (Yes/No) | No |
| Operating Temperature | -40°F to +248°F (-40°C to +120°C) |
| Reach Compliant (Article 33) | No |
| ROHS Compliant | Yes |
| Certification/Specification | Exova NFPA130: 2017 ASTM E 662 ASTM 1354 ASTM E 162 |
| Package Quantity (Imperial) | 100 |
| Package Quantity (Metric) | 100 |
| Customs Number | 3926909988 |

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach

to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

© 2023 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)