


## Specification Sheet

Part Number: MB410C2

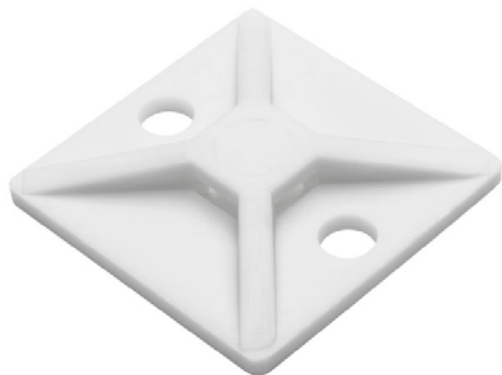

Screw Mount Cable Tie Base, 1.12" x 1.12", .18" Max Tie Width, .18" Hole Dia, PA66, White, 100/pkg

|                                |  |
|--------------------------------|--|
| <b>Article Number</b>          | 151-28802  |
| <b>Type</b>                    | MB4  |
| <b>Color</b>                   | White (WH)   |
| <b>Features &amp; Benefits</b> | <ul style="list-style-type: none"><li>•Compact size fits most mounting applications.</li><li>•Simple to install with a screw or rivet.</li><li>•Single hole attachment with two-way entry for cable tie.</li></ul>   |
| <b>Quantity Per</b>            | bag  |
| <b>Product Description</b>     | These cable tie mounts are compact in size. They are designed for simple yet robust installation. They pair with a cable tie for mounting applications including telecom equipment, switchgear and control cabinets. |
| <b>Short Description</b>       | Screw Mount Cable Tie Base, 1.12" x 1.12", .18" Max Tie Width, .18" Hole Dia, PA66, White, 100/pkg   |

Global Part Name

MB4-PA66-WH

Length L (Imperial)

1.12

Length L (Metric)

28.5

Fixation Method

Screw Mounting and Rivet

Width W (Imperial)

1.12

Width W (Metric)

28.5

Cable Ties

T18 - 50

Height H (Imperial)

.19

Height H (Metric)

4.80

Cable Tie Width Max (Imperial)

0.18

Cable Tie Width Max (Metric)

4.6

Mounting Hole Diameter D (Imperial)

0.18

Mounting Hole Diameter D (Metric)

4.6 mm

Mounting Hole Diameter D Max (Metric)

4.6

Mounting Hole Centers (Imperial)

0.79

|  |                                  |
|--|----------------------------------|
| <b>Material</b>                        | Polyamide 6.6 (PA66)             |
| <b>Material Shortcut</b>               | PA66                             |
| <b>Flammability</b>                    | UL 94 V2                         |
| <b>Operating Temperature (Metric)</b>  | -40°F to +185°F (-40°C to +85°C) |
| <b>ROHS Complaint</b>                  | Yes                              |
| <b>Certification/Specification WEB</b> | UL                               |
| <b>UL Recognized (US)</b>              | Yes                              |
| <b>UL Recognized (US and Canada)</b>   | Yes                              |
| <b>Package Quantity(Imperial)</b>      | 100                              |
| <b>Package Quantity (Metric)</b>       | 100                              |
| <b>Customs Number</b>                  | 3926909988                       |