


Specification Sheet

Part Number: 170-20800

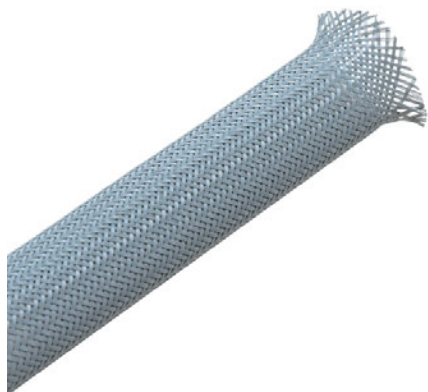

Helagaine Braided Sleeving, 8 mm Dia, PA66, GY, 328ft/Reel

| | |
|--------------------------------|--|
| Article Number | 170-20800 |
| Type | HEGPA6608 |
| Color | Gray (GY) |
| Features & Benefits | <ul style="list-style-type: none">• Nylon monofilament construction weave offers a tight braid that provides full coverage but will not rot or retain moisture.• Material performs well in wet applications and where abiding substrate has a smooth surface. |
| Quantity Per | metre |
| Product Description | Helagaine Nylon Polyamide Expandable Braided Sleeving is a pliable yet durable sleeve that protects against cuts, abrasion and excessive wear caused by repetitive motion. |
| Short Description | Helagaine Braided Sleeving, 8 mm Dia, PA66, GY, 328ft/Reel |
| Global Part Name | HEGPA6608-PA66-GY |

| | |
|---------------------------------------|-----------------------------------|
| Length L (Imperial) | 328.0 |
| Length L (Metric) | 100.0 |
| Bundle Diameter Min (Imperial) | 0.2 |
| Bundle Diameter Min (Metric) | 5 |
| Bundle Diameter Max (Imperial) | 0.4 |
| Bundle Diameter Max (Metric) | 10 |
| Diameter D (imperial) | 0.31 |
| Diameter D (metric) | 7.9 |
| Nominal Diameter (Imperial) | 5/16 |
| Nominal Diameter (Metric) | 8 |
| Material | Polyamide 6.6 (PA66) |
| Material Shortcut | PA66 |
| Flammability | FMVSS 302 UL 94 V2 |
| Halogen free | Yes |
| Operating Temperature (Metric) | -76°F to +302°F (-60°C to +150°C) |

Reach Complaint(Article 33) Yes

ROHS Complaint Yes

Certification/Specification WEB EN [45545-2]:2013

Package Quantity(Imperial) 328

Package Quantity (Metric) 100

Customs Number 5808100000

Content Unit(BMEcat) metre

Weight (Metric) 0.5

Weight (Imperial) 1.1