


## Specification Sheet

Part Number: 181-05518

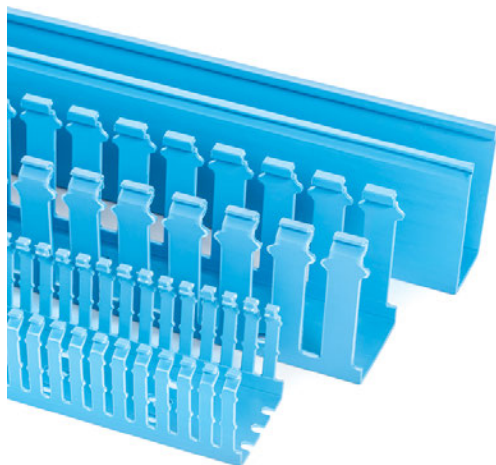

Solid Wall Wiring Duct, 1" x 1", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/carton

<b>Article Number</b>	181-05518
<b>Type</b>	SD1X1
<b>Color</b>	Intrinsic Blue (IBU)
<b>Features &amp; Benefits</b>	<ul style="list-style-type: none"><li>•Solid wall construction provides excellent coverage to keep wires clean.</li><li>•Durable material protects wires from damage, with long-lasting performance.</li><li>•Available standard colors complement or contrast in light and dark environments.</li><li>•Optional covers snap on and off easily, and are provided with a non-slip lining that insures the covers remain in place during vibration.</li></ul>
<b>Quantity Per</b>	carton

### Product Description

HellermannTyton's Pro-Duct, Solid Wall wiring duct efficiently routes and protects wire. Solid Wall wiring duct is designed for straight wire runs where break outs are not required. Pro-Duct, Solid Wall wiring duct is manufactured from high impact, rigid PVC, comes in standard colors of white, gray and black, and is available in 6-foot lengths.

<b>Short Description</b>	Solid Wall Wiring Duct, 1" x 1", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/carton
<b>Global Part Name</b>	SD1X1-PVC-BU
<b>Length L (Imperial)</b>	6.0
<b>Length L (Metric)</b>	1.83
<b>Width W (Imperial)</b>	1.0
<b>Width W (Metric)</b>	25.4
<b>Height H (Imperial)</b>	1.06
<b>Height H (Metric)</b>	26.90
<b>Mounting Hole Centers (Imperial)</b>	4.0
<b>Material</b>	Polyvinylchloride (PVC)
<b>Material Shortcut</b>	PVC
<b>Flammability</b>	Self-Extinguishing
<b>Halogen free</b>	No
<b>Operating Temperature (Metric)</b>	+122°F (+50°C)
<b>Reach Complaint(Article 33)</b>	No

<b>ROHS Complaint</b>	Yes
<b>Certification/Specification WEB</b>	CSA UL EN 50085-2-3_1A EN 50085-1:2005 + A1:2013
<b>UL Recognized (US)</b>	Yes
<b>Package Quantity(Imperial)</b>	120
<b>Package Quantity (Metric)</b>	36.58
<b>Customs Number</b>	3925900000