


Specification Sheet

Part Number: 184-05564

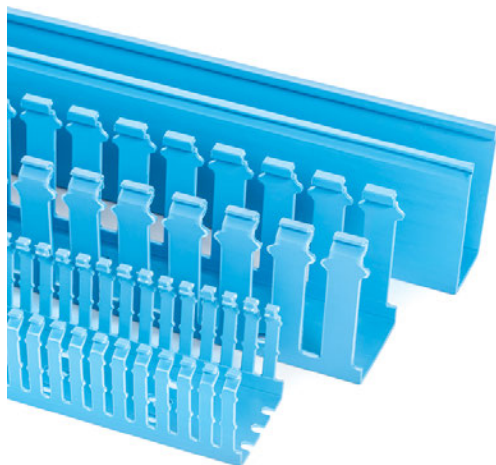

High-Density Slotted-Wall Wiring Duct, 4" x 2", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/ctn

Article Number	184-05564
Type	SLHD4X2
Color	Intrinsic Blue (IBU)
Features & Benefits	<ul style="list-style-type: none">•Narrow fingers reduce fanning of the wires to the terminal blocks, presenting a neater appearance.•Each finger is provided with a double restriction to hold wires in the bottom portion of the duct, allowing for easier installation.•Mounting holes are uniform in size and are offered every 2 inches to accommodate compact designs and ease installation.•Optional covers snap on and off easily, and are provided with a non-slip lining that insures the covers remain in place during vibration.
Quantity Per	carton

Product Description

HellermannTyton Pro-Duct High-Density, Slotted-Wall Wiring Duct features narrow fingers equaling a 2 to 1 finger ratio compared to standard slotted wiring duct. With the narrow fingers, compact designs and components are more easily accommodated.

Short Description	High-Density Slotted-Wall Wiring Duct, 4" x 2", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/ctn
Global Part Name	SLHD4X2-PVC-BU
Length L (Imperial)	6.0
Length L (Metric)	1.83
Width W (Imperial)	4.0
Width W (Metric)	101.6
Height H (Imperial)	2.07
Height H (Metric)	52.6
Mounting Hole Centers (Imperial)	2.0
Material	Polyvinylchloride (PVC)
Material Shortcut	PVC
Flammability	Self-Extinguishing
Halogen free	No
Operating Temperature (Metric)	+122°F (+50°C)
Reach Complaint(Article 33)	No

ROHS Complaint	Yes
Certification/Specification WEB	CSA EN 50085-2-3_1A EN 50085-1:2005 + A1:2013 UL
UL Recognized (US)	Yes
Package Quantity(Imperial)	120
Package Quantity (Metric)	36.58
Customs Number	3925900000