


## Specification Sheet

Part Number: 184-05603

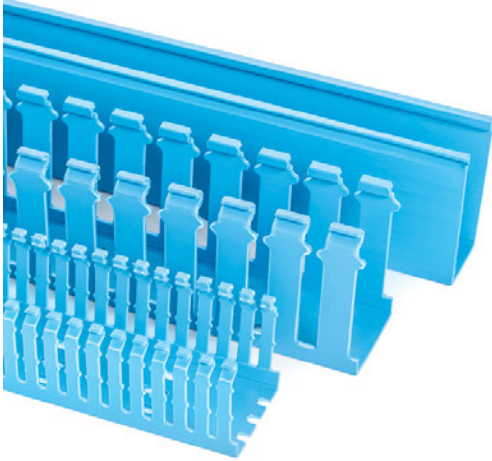

High-Density Slotted-Wall Wiring Duct, 4" x 4", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/ctn

Article Number	184-05603
Type	SLHD4X4
Color	Intrinsic Blue (IBU)
Features & Benefits	<ul style="list-style-type: none"><li>•Narrow fingers reduce fanning of the wires to the terminal blocks, presenting a neater appearance.</li><li>•Each finger is provided with a double restriction to hold wires in the bottom portion of the duct, allowing for easier installation.</li><li>•Mounting holes are uniform in size and are offered every 2 inches to accommodate compact designs and ease installation.</li><li>•Optional covers snap on and off easily, and are provided with a non-slip lining that insures the covers remain in place during vibration.</li></ul>
Quantity Per	carton

### Product Description

HellermannTyton Pro-Duct High-Density, Slotted-Wall Wiring Duct features narrow fingers equaling a 2 to 1 finger ratio compared to standard slotted wiring duct. With the narrow fingers, compact designs and components are more easily accommodated.

<b>Short Description</b>	High-Density Slotted-Wall Wiring Duct, 4" x 4", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/ctn
<b>Global Part Name</b>	SLHD4X4-PVC-BU
<b>Length L (Imperial)</b>	6.0
<b>Length L (Metric)</b>	1.83
<b>Width W (Imperial)</b>	4.0
<b>Width W (Metric)</b>	101.6
<b>Height H (Imperial)</b>	4.07
<b>Height H (Metric)</b>	103.4
<b>Mounting Hole Centers (Imperial)</b>	2.0
<b>Material</b>	Polyvinylchloride (PVC)
<b>Material Shortcut</b>	PVC
<b>Flammability</b>	Self-Extinguishing
<b>Halogen free</b>	No
<b>Operating Temperature (Metric)</b>	+122°F (+50°C)
<b>Reach Complaint(Article 33)</b>	No

<b>ROHS Complaint</b>	Yes
<b>Certification/Specification WEB</b>	CSA EN 50085-1:2005 + A1:2013 UL EN 50085-2-3_1A
<b>UL Recognized (US)</b>	Yes
<b>Package Quantity(Imperial)</b>	120
<b>Package Quantity (Metric)</b>	36.58
<b>Customs Number</b>	3925900000