


## Specification Sheet

Part Number: 184-22028

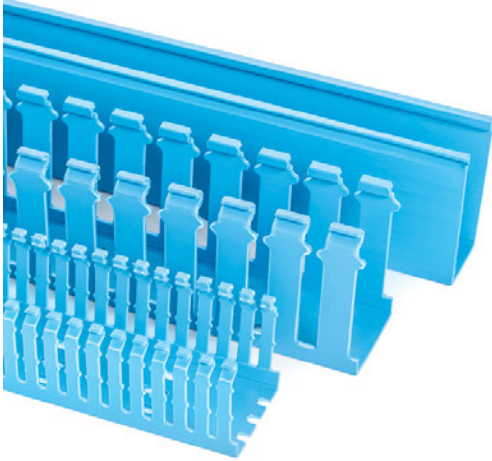

High-Density Slotted-Wall Wiring Duct, 2" x 5", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/ctn

|                     |   |
|---------------------|---|
| Article Number      | 184-22028   |
| Type                | SLHD2X5   |
| Color               | Intrinsic Blue (IBU)  |
| Features & Benefits | <ul style="list-style-type: none"><li>•Narrow fingers reduce fanning of the wires to the terminal blocks, presenting a neater appearance.</li><li>•Each finger is provided with a double restriction to hold wires in the bottom portion of the duct, allowing for easier installation.</li><li>•Mounting holes are uniform in size and are offered every 2 inches to accommodate compact designs and ease installation.</li><li>•Optional covers snap on and off easily, and are provided with a non-slip lining that insures the covers remain in place during vibration.</li></ul> |
| Quantity Per        | carton  |

### Product Description

HellermannTyton Pro-Duct High-Density, Slotted-Wall Wiring Duct features narrow fingers equaling a 2 to 1 finger ratio compared to standard slotted wiring duct. With the narrow fingers, compact designs and components are more easily accommodated.

|   |   |
|---|---|
| <b>Short Description</b>                | High-Density Slotted-Wall Wiring Duct, 2" x 5", Non-Adhesive, PVC, Intrinsic Blue, 120 ft/ctn |
| <b>Global Part Name</b>                 | SLHD2X5-PVC-BU  |
| <b>Length L (Imperial)</b>              | 6.0   |
| <b>Length L (Metric)</b>                | 1.83  |
| <b>Width W (Imperial)</b>               | 2.0   |
| <b>Width W (Metric)</b>                 | 50.8  |
| <b>Height H (Imperial)</b>              | 5.07  |
| <b>Height H (Metric)</b>                | 128.8   |
| <b>Mounting Hole Centers (Imperial)</b> | 2.0   |
| <b>Material</b>                         | Polyvinylchloride (PVC)   |
| <b>Material Shortcut</b>                | PVC   |
| <b>Flammability</b>                     | Self-Extinguishing  |
| <b>Halogen free</b>                     | No  |
| <b>Operating Temperature (Metric)</b>   | +122°F (+50°C)  |
| <b>Reach Complaint(Article 33)</b>      | No  |

|  |  |
|--|--|
| <b>ROHS Complaint</b>                  | Yes  |
| <b>Certification/Specification WEB</b> | EN 50085-1:2005 + A1:2013 UL CSA EN 50085-2-3_1A |
| <b>UL Recognized (US)</b>              | Yes  |
| <b>Package Quantity(Imperial)</b>      | 120  |
| <b>Package Quantity (Metric)</b>       | 36.58  |
| <b>Customs Number</b>                  | 3925900000                                       |