


## Specification Sheet

Part Number: 184-22050

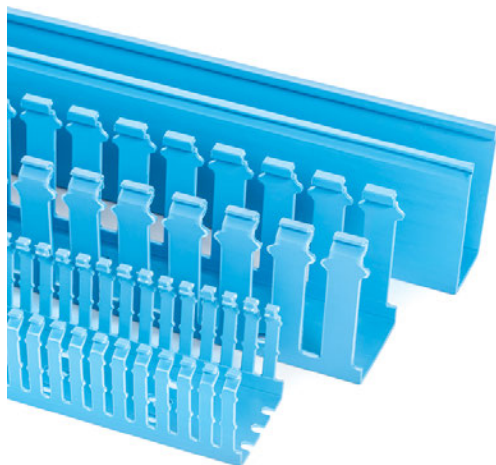

High-Density Slotted-Wall Wiring Duct, 2.5" x 3", Non- Adhesive, PVC, Intrinsic Blue, 120 ft/ctn

**Article Number**

184-22050

**Type**

SLHD2.5X3

**Color**

Intrinsic Blue (IBU)

### Features & Benefits

- Narrow fingers reduce fanning of the wires to the terminal blocks, presenting a neater appearance.
- Each finger is provided with a double restriction to hold wires in the bottom portion of the duct, allowing for easier installation.
- Mounting holes are uniform in size and are offered every 2 inches to accommodate compact designs and ease installation.
- Optional covers snap on and off easily, and are provided with a non-slip lining that insures the covers remain in place during vibration.

**Quantity Per**

carton

### Product Description

HellermannTyton Pro-Duct High-Density, Slotted-Wall Wiring Duct features narrow fingers equaling a 2 to 1 finger ratio compared to standard slotted wiring duct. With the narrow fingers, compact designs and components are more easily accommodated.

<b>Short Description</b>	High-Density Slotted-Wall Wiring Duct, 2.5" x 3", Non- Adhesive, PVC, Intrinsic Blue, 120 ft/ctn
<b>Global Part Name</b>	SLHD2.5X3-PVC-BU
<b>Length L (Imperial)</b>	6.0
<b>Length L (Metric)</b>	1.83
<b>Width W (Imperial)</b>	2.5
<b>Width W (Metric)</b>	63.5
<b>Height H (Imperial)</b>	3.07
<b>Height H (Metric)</b>	77.9
<b>Mounting Hole Centers (Imperial)</b>	2.0
<b>Material</b>	Polyvinylchloride (PVC)
<b>Material Shortcut</b>	PVC
<b>Flammability</b>	Self-Extinguishing
<b>Halogen free</b>	No
<b>Operating Temperature (Metric)</b>	+122°F (+50°C)
<b>Reach Complaint(Article 33)</b>	No

<b>ROHS Complaint</b>	Yes
<b>Certification/Specification WEB</b>	EN 50085-2-3_1A UL EN 50085-1:2005 + A1:2013 CSA
<b>UL Recognized (US)</b>	Yes
<b>Package Quantity(Imperial)</b>	120
<b>Package Quantity (Metric)</b>	36.58
<b>Customs Number</b>	3925900000