

Specification Sheet


Part Number: 184-44005

Narrow fingers reduce fanning of the wires to the terminal blocks, presenting a neater appearance.

Each finger is provided with a double restriction to hold wires in the bottom portion of the duct, allowing for easier installation.

Mounting holes are uniform in size and are offered every 2 inches to accommodate compact designs and ease installation.

Optional covers snap on and off easily, and are provided with a non-slip lining that insures the covers remain in place during vibration.

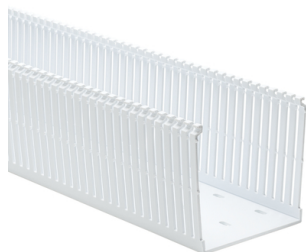

High Density Slotted Wall Wiring Duct, 4" x 4", Non-Adhesive, PVC, White, 7FT, 70ft/Carton

Article Number 184-44005

Type SLHD4X4

Color White (WH)

Quantity Per carton

Product Description HellermannTyton High-Density Slotted Wall Wiring Duct features narrow fingers equaling a 2-to-1 finger ratio compared to standard slotted wiring duct. With the narrow fingers, compact designs and components are more easily accommodated.

Short Description	High Density Slotted Wall Wiring Duct, 4" x 4", Non-Adhesive, PVC, White, 7FT, 70ft/Carton
Global Part Name	SLHD4X4-PVC-WH
Length L (Imperial)	7
Length L (Metric)	2.13
Width W (Imperial)	4.00
Width W (Metric)	101.60
Height H (Imperial)	4.07
Height H (Metric)	103.40
Mounting Hole Centers (Imperial)	2.00
Material	Polyvinylchloride (PVC)
Material Shortcut	PVC
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	+122°F (+50°C)

Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Certification/Specification	EN 50085-2-3_1A UL CSA EN 50085-1:2005 + A1:2013
UL Recognized (US)	Yes
Package Quantity (Imperial)	70.0
Package Quantity (Metric)	21.34
Customs Number	3925900000

© 2024 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)