


Specification Sheet

Part Number: 553-50072

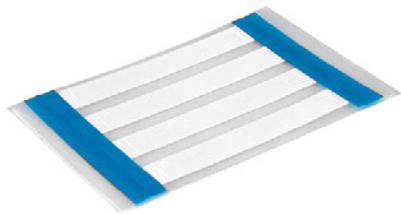

ShrinkTrak Labels, 1-Sided, 2-Slit, .187" (4.74mm), PO-X, White, 3000/box

Article Number	553-50072
Type	HST4.8-1.6WH-2S
Color	White (WH)
Features & Benefits	• Slide Slit and optional center slits for easy wire insertion. • Smooth surface for clean and legible printing. • Supplied on a ladder style carrier so that markers can be kitted after printing. • A 3:1 shrink ratio means fewer skews as each marker covers a wider range of wire diameters.
Quantity Per	box
Product Description	HellermannTyton's ShrinkTrak heat shrinkable markers make it easy to mark wire, cable and other components. The military approved heat shrink tubing is flattened and assembled in a ladder style carrier system for easy printing using a thermal transfer printer. The ladder system creates a kit of markers that can be sorted, removed and applied in any order thus saving time, labor and speeding production.

Short Description	ShrinkTrak Labels, 1-Sided, 2-Slit, .187" (4.74mm), PO-X, White, 3000/box
Global Part Name	HST4.8-1.6WH-2S-PO-X-WH
Variant	Thin-Wall
Width W (Imperial)	0.633
Width W (Metric)	16.08
Thickness T (Imperial)	.003
Thickness T (Metric)	.0762
Height H (Imperial)	0.312
Height H (Metric)	7.92
Width of Liner (Metric)	76.2
Width of Liner (imperial)	3.0
Outside Diameter OD(Imperial)	0.187
Outside Diameter OD(metric)	4.74
Outside Diameter Max(Imperial)	0.187
Outside Diameter Max (metric)	4.74
Wall Thickness WT (Imperial)	0.026
Wall Thickness WT (Metric)	0.66

Material	Polyolefin, cross-linked (PO-X)		
Material Shortcut	PO-X		
US MIL SPEC	SAE-AS81531		
SAE-AMS-DTL-23053/5 Class 1 and 3			
MIL-STD-202G Method 215K			
Flammability			
UL 224 VW-1		Halogen free	
No		Operating Temperature (Metric)	
-67°F to +275°F (-55°C to +135°C)		Reach Complaint(Article 33)	
Yes		ROHS Complaint	
Yes		Certification/Specification WEB	
CEN			
Package Quantity(Imperial)	3000		
Package Quantity (Metric)	3000		
Customs Number	3917320000		
Content Unit(BMEcat)	pack		
Labels per Column	1		

Labels per Row

3

Weight (Metric)

0.635

Weight (Imperial)

1.36