


Specification Sheet

Part Number: 596-00865

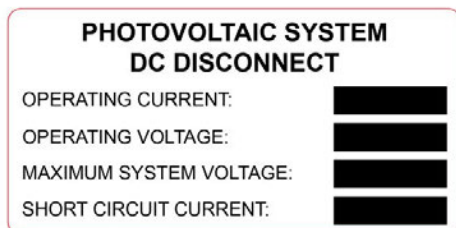

Metal Solar Placard, Engravable, DC Rating Label, 4.0" x 2.0", AL, Black, 5/pkg

Article Number	596-00865
Type	DCRATINGM5ENG
Color	Black (BK)
Features & Benefits	<ul style="list-style-type: none">• Placards made with UV stable inks and materials tested to last up to 25 years, even in direct sun exposure.• Aggressive adhesive ensures strong bond, even on powder coated surfaces.• Meets or exceeds NEC & IFC standards for printed text, character height, color and outdoor UV stability.• Optional Paint Shields provide additional protection for pre-printed and variable data placards.
Quantity Per	pcs.

Product Description

Variable data placards are used to mark areas specific to the individual installation, like voltage data. Made of the same durable material as pre-printed metal solar placards, HellermannTyton offers two styles of variable placards: hand-writable and engravable. Both hand-writable placards feature a silver variable data area that can be marked using an industrial paint pen. Engravable placards have a black area that can be engraved using standard engraving equipment.

Short Description

Metal Solar Placard, Engravable, DC Rating Label, 4.0" x 2.0", AL, Black, 5/pkg

Global Part Name

DCRATINGM5ENG-AA-BK

Technical Description

Pre-Printed Metal Solar Placard, 2008 DC Rating Label for engraving", 4.0" X 2.00", Black

Local Order Number 2

Cross Reference = Paint Shield: 596-00794

Length L (Imperial)

2.00

Length L (Metric)

50.8

Width W (Imperial)

4.0

Width W (Metric)

101.6

Height H (Imperial)

2.0

Height H (Metric)

50.80

Material

Anodized Aluminum (AA)

Material Shortcut

AA

Adhesive	Ultra High Bond Permanent Acrylic Adhesive
Halogen free	No
Adhesive Operating Temperature	from +50°F (from +10°C)
Operating Temperature (Metric)	-40°F to +203°F (-40°C to +95°C)
Reach Complaint(Article 33)	Yes
ROHS Complaint	Yes
Certification/Specification WEB	NEC2014
Warranty (US)	Yes
Package Quantity(Imperial)	5
Package Quantity (Metric)	5
Customs Number	3919905060
Labels per Column	1
Labels per Row	1
Weight (Metric)	.104
Weight (Imperial)	0.23

