


## Specification Sheet

Part Number: 596-00920

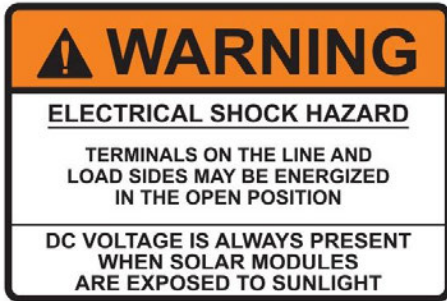

Article Number

596-00920

Type

WESHLBLDC17M5

Color

Orange (OG)

### Features & Benefits

- Placards made with UV stable inks and materials tested to last up to 25 years, even in direct sun exposure.
- Aggressive adhesive ensures strong bond, even on powder coated surfaces.
- Meets or exceeds NEC & IFC standards for printed text, character height, color and outdoor UV stability.
- Optional Paint Shields provide additional protection for pre-printed and variable data placards.

Quantity Per

pack

### Product Description

Variable data placards are used to mark areas specific to the individual installation, like voltage data. Made of the same durable material as pre-printed metal solar placards, HellermannTyton offers two styles of variable placards: hand-writable and engravable. Both hand-writable placards feature a silver variable data area that can be marked using an industrial paint pen. Engravable placards have a black area that can be engraved using standard engraving equipment.

<b>Short Description</b>	Metal Solar Placard, 2017 Code, WARNING ELECTRICAL...DC VOLTAGE, 3.75" x 2.5", AL,Orange/Silver,5/pkg
<b>Global Part Name</b>	WESHLBLDC17M5-AA-OG
<b>Technical Description</b>	3.75" X 2.5" Black text on an Orange/Silver Aluminum background that reads as: "WARNING ELECTRICAL SHOCK HAZARD. TERMINALS ON BOTH LINE AND LOAD SIDE MAY BE ENERGIZED IN THE OPEN POSITION. DC VOLTAGE IS ALWAYS PRESENT WHEN SOLAR MODULES ARE EXPOSED TO SUNLIGHT" - 5 per pack
<b>Length L (Imperial)</b>	2.5
<b>Length L (Metric)</b>	63.5
<b>Width W (Imperial)</b>	3.75
<b>Width W (Metric)</b>	95.25
<b>Thickness T (Metric)</b>	64.0
<b>Height H (Imperial)</b>	2.50
<b>Height H (Metric)</b>	63.50
<b>Material</b>	Anodized Aluminum (AA)
<b>Material Shortcut</b>	AA
<b>Adhesive</b>	Ultra High Bond Permanent Acrylic Adhesive

<b>Halogen free</b>	No
<b>Adhesive Operating Temperature</b>	from +50°F (from +10°C)
<b>Operating Temperature (Metric)</b>	-40°F to +203°F (-40°C to +95°C)
<b>Reach Complaint(Article 33)</b>	Yes
<b>ROHS Complaint</b>	Yes
<b>Certification/Specification WEB</b>	NEC2017
<b>Warranty (US)</b>	Yes
<b>Package Quantity(Imperial)</b>	5
<b>Package Quantity (Metric)</b>	5
<b>Customs Number</b>	3919102055
<b>Labels per Column</b>	1
<b>Labels per Row</b>	1
<b>Weight (Metric)</b>	.104
<b>Weight (Imperial)</b>	0.23

