


## Specification Sheet

Part Number: P108-48-MOD

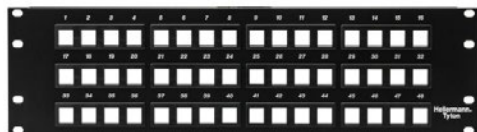

Modular Patch Panel 48 Port, 3U, Steel, Black, 1/box

**Article Number**

853-19205

**Type**

P108-48-MOD

**Color**

Black (BK)

**Features & Benefits**

- The modular design provides flexibility with the panel for customization of different applications including coax, voice, audio, video and fiber.
- Once the connectors are snapped into the panel, they are flush with the front of the plate providing an aesthetic look.

**Quantity Per**

box

**Product Description**

The modular patch panel is designed to accept HellermannTyton Category 6A, 6 and 5e UTP modular jacks and connectors, providing flexibility in multimedia installations. These modular panels can be mounted to any standard EIA 19" rack, cabinet or wall mount patch panel bracket. HellermannTyton pre-numbered modular patch panels are available in 12, 16, 24, 32 and 48 port configurations.

**Short Description**

Modular Patch Panel 48 Port, 3U, Steel, Black, 1/box

**Global Part Name**

P108-48-MOD

**Technical Description**

Modular Patch Panel 48 Port, 3U, Steel, Black

**Length L (Imperial)**

19.0

**Length L (Metric)**

482.6

**Height H (Imperial)**

5.25

**Height H (Metric)**

133.35

**Material**

Steel (ST)

**Material Shortcut**

ST

**UL Listed (US and Canada)**

Yes

**UL Listed (US**

Yes

**Package Quantity(Imperial)**

1

**Package Quantity (Metric)**

1

**Customs Number**

9030400000

---

© 2019 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)