

# Thermometers and Gauges

## Sweat and Threaded Thermometers with Thermowells



### Thermometer with Sweat or Threaded Connection.

- Brass thermowell is included to allow the thermometer to be removed without draining the system.
- 2 inch or 2 1/2 inch Dial.

**Materials:** Case: steel; Well: brass

**Temperature Range:** 32 F to 250 F (0 C to 121 C)

**Connection Size:** 1/2 in.


Product Number	Connection Type	Dial Size		Length		Weight	
		inch	mm	inch	mm	lb	kg
GS200/U	Sweat	2 in.	51 mm	1 1/4 in.	51 mm	0.21 b	0.095 kg
GS250/U	Sweat	2 1/2 in.	63.5 mm	1 1/4 in.	51 mm	0.25 b	0.114 kg
GT161/U	NPT	2 in.	51 mm	1 1/2 in.	51 mm	0.21 b	0.095 kg
GT162/U	NPT	2 1/2 in.	63.5 mm	1 1/2 in.	51 mm	0.25 b	0.114 kg

## Tridicators



Pressure/temperature gauge with relief set point indicator for boilers and shut off valve.

### Dimensions Diagram

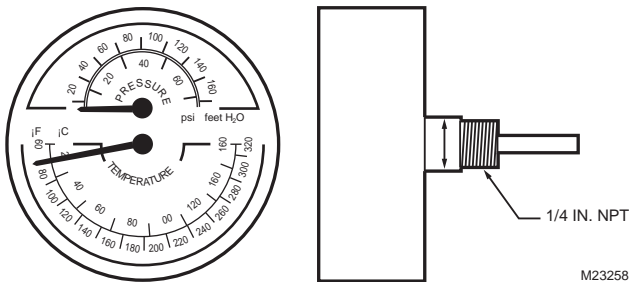

**Temperature Range:** 60 F to 320 F (15 C to 160 C)

**Connection Size:** 1/4 in.

**Maximum Operating Pressure:** 75 psi

Product Number	Connection Type	Dial Size		Length		Weight		Comments
		inch	mm	inch	mm	lb	kg	
TD-090/U	NPT	3 1/8 in.	79.4 mm	1 21/32 in.	23 mm	0.3 b	0.14 kg	Pressure/temperature gauge with relief set point indicator
TD-165/U	NPT	3 1/8 in.	79.4 mm	2 in.	42.1 mm	0.3 b	0.14 kg	Pressure/temperature gauge with relief set point indicator
TDV-040/U	NPT	3 1/8 in.	79.38 mm	29/32 in.	23.02 mm	0.4 b	0.18 kg	Pressure/temperature gauge with relief set point indicator and shut off valve