


Zone Control Damper Accessories

AT140 Universal Mount Transformer

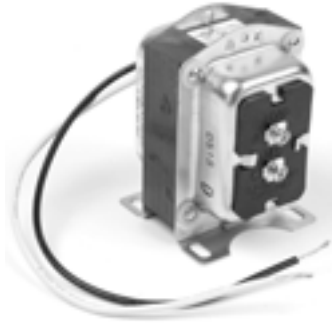

The AT140 is a 24V, 40VA universal mount transformer.

- Provides a low voltage power source for any Honeywell zone control panel or damper
- Powers up to 5 ZD or ARD damper motors and 14 RRD damper motors from one 40VA transformer
- Mounting options include plate or foot mounting
- 120/240 VAC primary

Application: Accessory

Product Number	Voltage
AT140A1042/U	120/240V Primary, 24V Secondary 40VA

M847D Damper Actuator



The M847D is a two position, 24 Vac spring return actuator designed to operate ARD, EARD and ZD zone dampers.

- Low voltage, spring-return damper actuator
- Equipped with anti-rotation and drive shaft extensions for direct mounting to 7/16 inch diameter coupling style dampers
- Adjustable range stops
- Direct replacement for M847D1004

Application: Damper Actuator

Voltage: 24V

Wires to Motor: 2

Motor Timing: 30 seconds powered/10 seconds spring return

Other Motor Information: Range stops

Product Number	Motor Mount	Motor Type	Description
M847D1012/U	Direct connection to damper shaft	Spring return	Spring Return Damper Actuator