

# Air Vents and Eliminators


## EA79 Industrial Air Vents




The Honeywell EA79 Industrial Air Vent purges air from high pressure mains and equipment in hot or cold closed water systems.

- Built-in shutoff valve for servicing without system shutdown.
- Built-in vacuum breaker.
- Removable float/valve assembly for easy servicing.
- Safety drain connection and vent cap with leakage guard.
- Brass shell construction.
- Internal parts made of corrosion-resistant and chemical-resistant materials for use with water systems containing propylene glycol, mineral oils, or petroleum-based oils. Replaces Hoffman # 79 or Dole # 75 Vents.
- Maintains quiet and efficient operation.


### Dimensions in inches (millimeters)

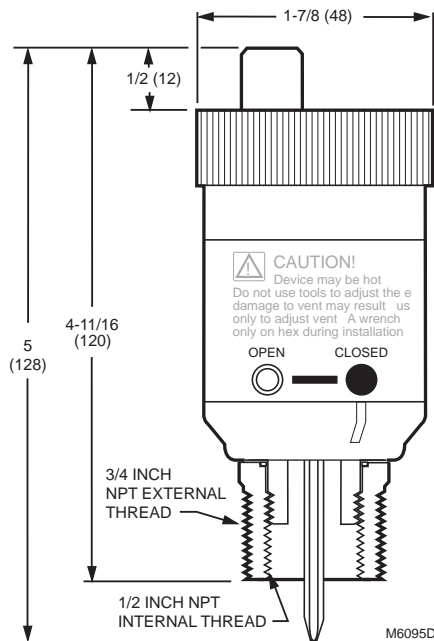

### EA79 construction

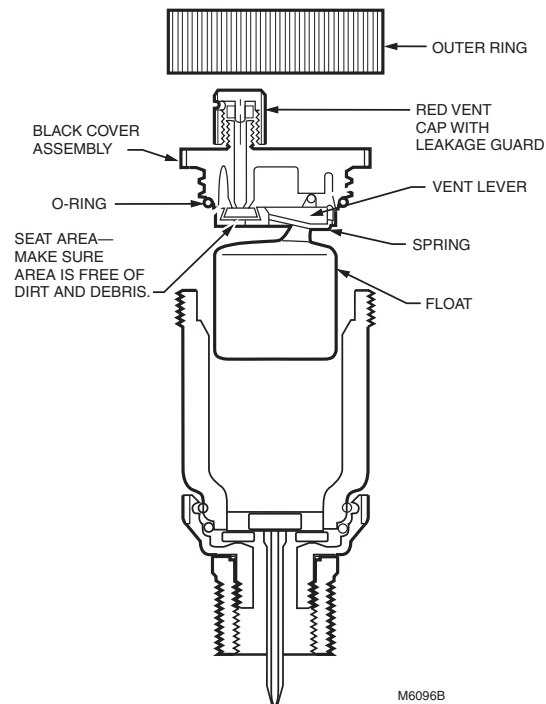

### EA79 capabilities

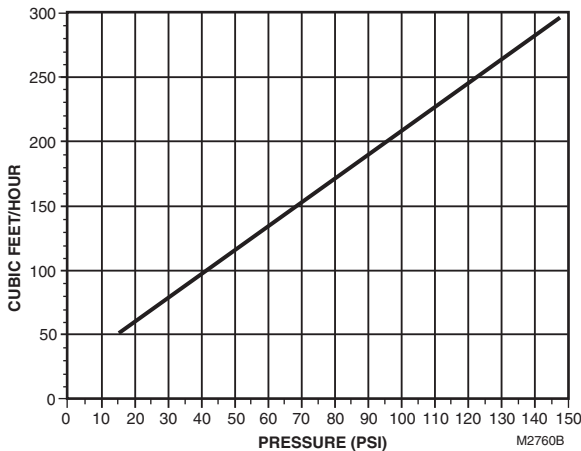

**Application:** Hydronics

**Corrosion Resistant:** Internal parts made of corrosion-resistant and chemical-resistant materials for use with hydronic systems that may contain concentrations of propylene or ethylene glycol.

**Maximum Operating Temperature:** 250 F (120C)

**Maximum Operating Pressure:** 150 psi (1034 kPa)

#### Accessories:

**Q122A1001**-Safe waste connector (M20 thread connection)

#### Replacement Parts:

**P79B1003**-Replacement O-ring, cover and internals for EA79A1004

Product Number	Connection Type	Connection Size	Description
EA79A1004	3/4 in. male NPT pipe thread with 1/2 in. female NPT pipe thread	3/4 in.	Industrial automatic air vent