


HP970 and TP970 Series Standard Covers and Accessories

SPECIFICATION DATA

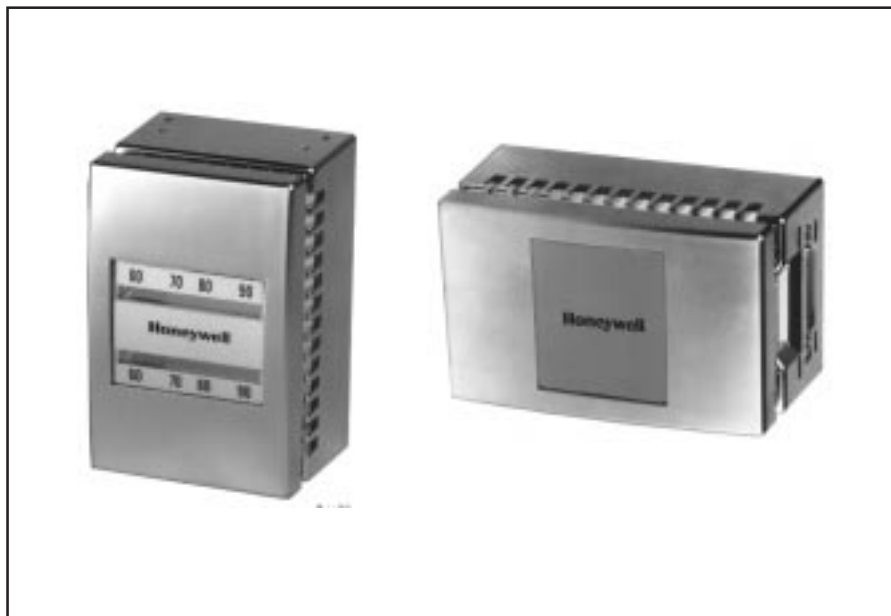

FEATURES

- Compact cover design for aesthetic appearance
- Available with or without setpoint opening for tamper resistance
- Satin chrome, bright chrome, satin brass, bright brass, or beige finish for a variety of decors
- Setpoint only, thermometer only, both setpoint and thermometer, or blank display for a variety of applications
- Available with large-scale numerals for the visually impaired

GENERAL

These covers and accessories are for use with the HP970 and TP970 Series Humidistats, Thermostats, and Sensors. The covers protect mechanisms from dust and damage and are designed for either vertical or horizontal mounting.




SPECIFICATIONS

Covers

Material:
Acrylonitrile Butadiene Styrene



Dimensions:
TP979 Dual Thermostat Covers: 3-3/8 in. (86 mm) high by 3-7/8 in. (99 mm) wide by 1-7/8 in. (48 mm) deep
Other Covers: 3-1/4 in. (83 mm) high by 2 in. (51 mm) wide by 1-5/8 in. (42 mm) deep

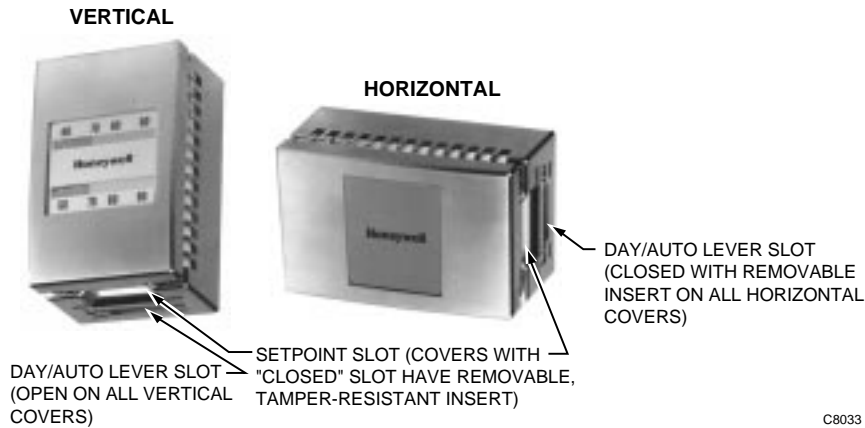Mounting:








C8033

Bright Chrome Covers:

Cover	Display (Unit)		Part Number 14004787-XXX ¹			
			Honeywell Logo			
			Setpoint Slot			
			Open		Closed	
			Mounting		Mounting	
Thermometer	Setpoint	Vert	Horiz	Vert	Horiz	
 RC158	None	None	-100	—	—	—
 RC159	60-90 (F)	60-90 (F)	-111	—	—	—

¹ When ordering, use complete part number including three-digit suffix.

Satin Chrome Covers:



Cover	Display (Unit)		Part Number 14004406-XXX ¹							
			Honeywell Logo				No Logo			
			Setpoint Slot				Setpoint Slot			
			Open		Closed		Open		Closed	
			Mounting		Mounting		Mounting		Mounting	
Thermometer	Setpoint	Vert	Horiz	Vert	Horiz	Vert	Horiz	Vert	Horiz	
 RC158	None	None	—	—	-300	-400	—	—	²	-800
 RC159	15-30 (C)	15-30 (C)	-110	-210	-310	—	-510	—	—	—
	60-90 (F)	69-90 (F)	-111	-211	-311	—	-511	-611	-711	—
	40-70 (F)	40-70 (F)	-112	—	—	—	—	—	—	—
	60-90 (F)	Heat range/ Cool range 60-90 (F)	-114	—	—	—	—	—	—	—
 RC158	69-90 (F) ³	60-90 (F) ³	-115	—	—	—	—	—	—	—
 RC160	None	15-30 (C)	-120	—	-320	—	—	—	—	—
	None	60-90 (F)	-121	—	-321	—	—	—	—	—
	None	40-70 (F)	-122	—	—	—	—	—	—	—
	None	COOLER/ WARMER	-123	—	—	—	—	—	—	—
	None	HUMIDITY 20-70 (% RH)	-124	-224	-324	-424	—	—	—	—
 RC163	15-30 (C)	None	—	—	-330	—	—	—	—	—
	60-90 (F)	None	—	—	-331	—	—	—	—	—

¹ When ordering, use complete part number including three-digit suffix.

² 14004406-800 Cover also suitable for vertical mounting.



³ Display has large-scale numerals for the visually impaired.

Satin Brass Covers:

Cover	Display (Unit)		Part Number 14004788-XXX ¹							
			Honeywell Logo				No Logo			
			Setpoint Slot				Setpoint Slot			
			Open		Closed		Open		Closed	
			Mounting		Mounting		Mounting		Mounting	
Thermometer	Setpoint	Vert	Horiz	Vert	Horiz	Vert	Horiz	Vert	Horiz	
 RC158	None	None	-100	—	—	—	-500	—	—	—
 RC159	60-90 (F)	60-90 (F)	-111	—	—	—	—	—	—	—




¹ When ordering, use complete part number including three-digit suffix.

Bright Brass Covers:

Cover	Display (Unit)		Part Number 14004789-XXX ¹			
			Honeywell Logo			
			Setpoint Slot			
			Open		Closed	
			Mounting		Mounting	
Thermometer	Setpoint	Vert	Horiz	Vert	Horiz	
 RC158	None	None	-100	—	—	—
 RC159	60-90 (F)	60-90 (F)	-111	—	—	—

¹ When ordering, use complete part number including three-digit suffix.

Beige Covers:





Cover	Display (Unit)		Part Number 14004407-XXX ^{1 2}							
			Honeywell Logo				No Logo			
			Setpoint Slot		Setpoint Slot		Setpoint Slot		Setpoint Slot	
			Open	Closed	Open	Closed	Open	Closed	Open	Closed
			Mounting		Mounting		Mounting		Mounting	
Thermometer	Setpoint	Vert	Horiz	Vert	Horiz	Vert	Horiz	Vert	Horiz	
 RC158	None	None	—	—	-300	-400	—	—	³	-800
 RC159	15-30 (C)	15-30 (C)	-10	-210	—	—	—	—	—	—
	60-90 (F)	60-90 (F)	-111	—	-311	—	-511	—	—	—
	60-90 (F)	15-30 (C)	-113	—	—	—	—	—	—	—
 RC160	None	60-90 (F)	-121	—	—	—	—	—	—	—
	None	HUMIDITY 20-70 (% rh)	-124	—	—	—	—	—	—	—

¹ When ordering, use complete part number including three-digit suffix.

² 14004407-XXX Covers are paintable. For painting information, see HP970-72 and TP970-74 Pneumatic Sensors, Humidistats, and Thermostats Installation Instructions 95-5597.

³ 14004407-800 Cover also suitable for vertical mounting.

TP979 Dual Thermostat Covers:

Cover	Display (Units)		Part No. Satin Chrome 14004756-XXX ¹ or Beige Plastic 14004757-XXX ¹	
			Setpoint Slot ²	
	Thermometer	Setpoint	Open	Closed
 RC164	None	None	—	-007 -008 ³
 RC165	60-90 (F)	60-90 (F) HEAT 60-90 (F) COOL	-001	—
	15-30 (C)	15-30 (C) HEAT 15-30 (C) COOL	-002	—
 RC166	None	60-90 (F) HEAT 60-90 (F) COOL	-003	—
	None	15-30 (C) HEAT 15-30 (C) COOL	-004	—
 RC167	60-90 (F)	None	—	-005
	15-30 (C)	None	—	-006

¹ When ordering, use complete part number including three-digit suffix.

² DAY/AUTO lever slot is open (not covered) on all models.

³ Does not have Honeywell logo.

NOTE: Beige Plastic Covers are paintable. For painting instructions, see TP979A-E Dual Zero Energy Band Pneumatic Thermostats Installation Instructions 95-6023.

Accessories

305965 Gage:



RC182

CCT729 Gage Port Needle:



RC168

CCT735A Thermostat Tool:



RC176

14002424-002, -003 Aspirating Wall Boxes and AK3970 Aspirator Box Cover:

Box and Cover ordered separately (see TP970 Series Thermostats Aspirating Wall Box Specification Data 77-9830)



RC178


RC177

14002430-001 Heavy Duty Thermostat Guard:
(Not applicable for TP979 Dual Thermostats)




RC181

14004437-001 (Satin Chrome), -002 (Beige Plastic) DAY/AUTO Cover Inserts:

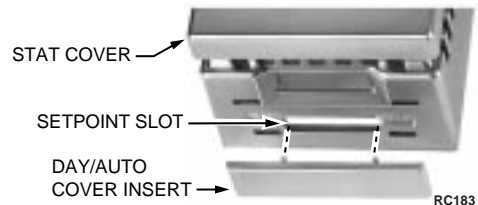


RC183

14004438-001 (Satin Chrome), -002 (Beige Plastic) Setpoint Cover Inserts; 14004437-XXX Setpoint Cover Inserts for TP979 Dual Thermostats:

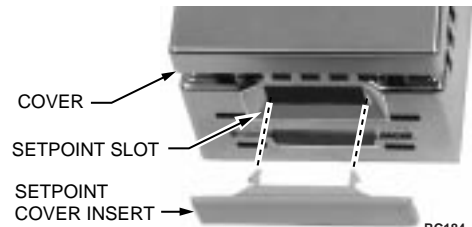

RC184

14004439-001 Setpoint Extension (for Thermostats Only):

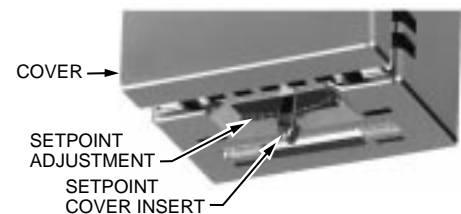

RC185

14002362-001 Duct Sampling Chamber:



RC180

AK3996C Duct Mounting Bracket:



RC179

14004908-001 Setpoint Stops for TP973 (bag of 10 for 5 thermostats)



C7868

By using this Honeywell literature, you agree that Honeywell will have no liability for any damages arising out of your use or modification to, the literature. You will defend and indemnify Honeywell, its affiliates and subsidiaries, from and against any liability, cost, or damages, including attorneys' fees, arising out of, or resulting from, any modification to the literature by you.

Home and Building Control
Honeywell Inc.

Home and Building Control
Honeywell Limited-Honeywell Limitée

Honeywell Asia Pacific Inc.

Sun Hung kai Centre

North Oak, Ontario

Honeywell Latin American Division

Honeywell Europe S.A.

Honeywell

Helping You Control Your World

