

Straight Blade Devices

Residential Grade Duplex and Decorator Receptacles

15A 125V Duplex and Decorator Weather Resistant and Tamper-Resistant Receptacles




Product Dimensions Inches (mm)

	Duplex	Decorator	Single	Single Decorator
A	4.19" (106.4)	4.19" (106.4)	4.20" (106.7)	4.20" (106.7)
B	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)
C	1.41" (35.8)	—	1.41" (35.8)	—
D	0.93" (23.6)	0.93" (23.6)	1.01" (25.7)	1.01" (25.7)
E	2.62" (66.6)	2.62" (66.6)	2.08" (52.8)	2.08" (52.8)


Wiring		Push and Side Wired	
Grounding		Self-Grounding	
Rating	Color	Duplex	Decorator
NEMA 5-15, 15A 125V	Black	RR15SBKWRTR	RRD15SBKWRTR
	Brown	RR15SWRTR	RRD15SWRTR
	Gray	RR15SGYWRTR	RRD15SGYWRTR
	Ivory	RR15SIWRTR	RRD15SIWRTR
	Light Almond	RR15SLAWRTR	RRD15SLAWRTR
	White	RR15SWRTR	RRD15SWRTR

Note: See page R-6 for tamper-resistant and weather resistant descriptions.

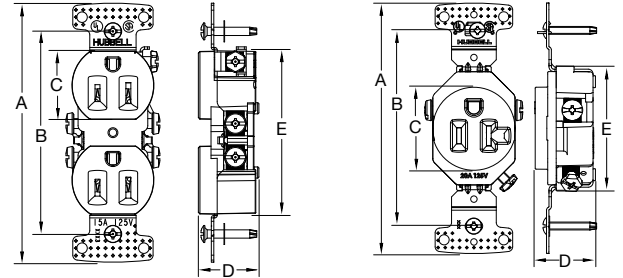

Residential Grade Single and Single Decorator Receptacles

15A and 20A 125V and 250V Single Self-Grounding Receptacles

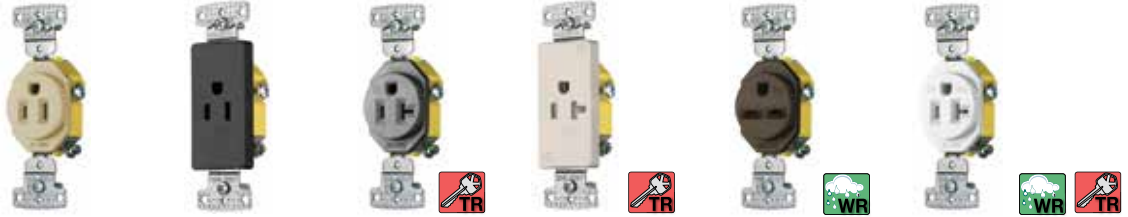

Style		Standard		Tamper-Resistant		Weather Resistant	Weather Resistant Tamper-Resistant
Rating	Color	Duplex	Decorator	Duplex	Decorator	Duplex	Duplex
NEMA 5-15, 15A 125V	Black	RR151BK	RRD151BK	RR151BKTR	RRD151BKTR	—	RR151BKWRTR
	Brown	RR151	RRD151	RR151TR	RRD151TR	—	RR151WRTR
	Gray	RR151GY	RRD151GY	RR151GYTR	RRD151GYTR	—	RR151GYWRTR
	Ivory	RR151I	RRD151I	RR151ITR	RRD151ITR	—	RR151IWRTR
	Light Almond	RR151LA	RRD151LA	RR151LATR	RRD151LATR	—	RR151LAWRTR
	White	RR151W	RRD151W	RR151WTR	RRD151WTR	—	RR151WWRTR
NEMA 5-20, 20A 125V	Black	RR201BK	RRD201BK	RR201BKTR	RRD201BKTR	—	RR201BKWRTR
	Brown	RR201	RRD201	RR201TR	RRD201TR	—	RR201WRTR
	Gray	RR201GY	RRD201GY	RR201GYTR	RRD201GYTR	—	RR201GYWRTR
	Ivory	RR201I	RRD201I	RR201ITR	RRD201ITR	—	RR201IWRTR
	Light Almond	RR201LA	RRD201LA	RR201LATR	RRD201LATR	—	RR201LAWRTR
	White	RR201W	RRD201W	RR201WTR	RRD201WTR	—	RR201WWRTR
NEMA 6-15, 15A 250V	Black	RR155BK	RRD155BK	—	—	RR155BKWR	—
	Brown	RR155	RRD155	—	—	RR155WR	—
	Gray	RR155GY	RRD155GY	—	—	RR155GYWR	—
	Ivory	RR155I	RRD155I	—	—	RR155IWR	—
	Light Almond	RR155LA	RRD155LA	—	—	RR155LAWR	—
White	RR155W	RRD155W	—	—	RR155WWR	—	
NEMA 6-20, 20A 250V	Black	RR205BK	RRD205BK	—	—	RR205BKWR	—
	Brown	RR205	RRD205	—	—	RR205WR	—
	Gray	RR205GY	RRD205GY	—	—	RR205GYWR	—
	Ivory	RR205I	RRD205I	—	—	RR205IWR	—
	Light Almond	RR205LA	RRD205LA	—	—	RR205LAWR	—
	White	RR205W	RRD205W	—	—	RR205WWR	—