

Straight Blade Devices  
**15 and 20 Ampere, 125 Volts**  
 2 Pole, 3 Wire Grounding  
**Commercial Specification Grade  
 Duplex Receptacles**





**15A 125V**  
 NEMA 5-15R  
 UL CSA  
 0.5 HP




**20A 125V**  
 NEMA 5-20R  
 UL CSA  
 1 HP

## Receptacles


### Commercial, Specification Grade, Duplex, Back and Side Wired

Description	Color	Catalog Number		
Smooth nylon face.	Almond	<b>BR15AL</b>	<b>BR20AL</b>	
	Black	<b>BR15BLK</b>	<b>BR20BLK</b>	
	Brown	<b>BR15</b>	<b>BR20</b>	
	Gray	<b>BR15GRY</b>	<b>BR20GRY</b>	
	Ivory	<b>BR15I</b>	<b>BR20I</b>	
	Light Almond	<b>BR15LA</b>	<b>BR20LA</b>	
	Office White	<b>BR15OW</b>	<b>BR20OW</b>	
	White	<b>BR15WHI</b>	<b>BR20WHI</b>	
	 Tamper-Resistant*, smooth nylon face.	Almond	<b>BR15ALTR</b>	<b>BR20ALTR</b>
		Black	<b>BR15BLKTR</b>	<b>BR20BLKTR</b>
Brown		<b>BR15TR</b>	<b>BR20TR</b>	
Gray		<b>BR15GRYTR</b>	<b>BR20GRYTR</b>	
Ivory		<b>BR15ITR</b>	<b>BR20ITR</b>	
Light Almond		<b>BR15LATR</b>	<b>BR20LATR</b>	
White		<b>BR15WHITR</b>	<b>BR20WHITR</b>	
 Weather-Resistant, smooth nylon face.		Almond	<b>BR15ALWR</b>	<b>BR20ALWR</b>
		Black	<b>BR15BLKWR</b>	<b>BR20BLKWR</b>
		Brown	<b>BR15WR</b>	<b>BR20WR</b>
	Gray	<b>BR15GRYWR</b>	<b>BR20GRYWR</b>	
	Ivory	<b>BR15IWR</b>	<b>BR20IWR</b>	
	Light Almond	<b>BR15LAWR</b>	<b>BR20LAWR</b>	
	White	<b>BR15WHIWR</b>	<b>BR20WHIWR</b>	
	 Weather and Tamper- Resistant*, smooth nylon face.	Almond	<b>BR15ALWRTR</b>	<b>BR20ALWRTR</b>
		Black	<b>BR15BLKWRTR</b>	<b>BR20BLKWRTR</b>
		Brown	<b>BR15WRTR</b>	<b>BR20WRTR</b>
Gray		<b>BR15GRYWRTR</b>	<b>BR20GRYWRTR</b>	
Ivory		<b>BR15IWRTR</b>	<b>BR20IWRTR</b>	
Light Almond		<b>BR15LAWRTR</b>	<b>BR20LAWRTR</b>	
White		<b>BR15WHIWRTR</b>	<b>BR20WHIWRTR</b>	
Isolated ground(1), smooth nylon face, side wired only.		Almond	<b>IG15CRAL</b>	<b>IG20CRAL</b>
		Gray	<b>IG15CRGRY</b>	<b>IG20CRGRY</b>
		Ivory	<b>IG15CRI</b>	<b>IG20CRI</b>
	Light Almond	<b>IG15CRLA</b>	<b>IG20CRLA</b>	
	White	<b>IG15CRWHI</b>	<b>IG20CRWHI</b>	
Isolated ground(1), Style Line® decorator*, smooth nylon face.	Almond	<b>IG15DRAL</b>	<b>IG20DRAL</b>	
	Gray	<b>IG15DRGRY</b>	<b>IG20DRGRY</b>	
	Ivory	<b>IG15DRI</b>	<b>IG20DRI</b>	
	Light Almond	<b>IG15DRLA</b>	<b>IG20DRLA</b>	
	White	<b>IG15DRWHI</b>	<b>IG20DRWHI</b>	


Note: (1) See Section J for complete line of isolated ground devices.  
 \* Tamper-resistant and IG decorator devices are not Fed. Spec. Listed.  
 See page A-15 for NEC® Tamper and Weather-Resistant Code Requirements.  
 See page A-46 for accessories.  
 See page A-57 for technical information.  
 See Section K for wallplates.

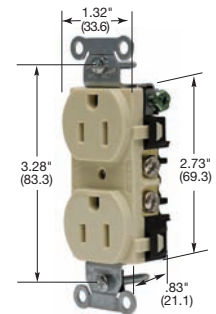


**BR15I**

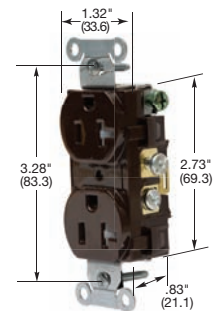


**BR20TR**

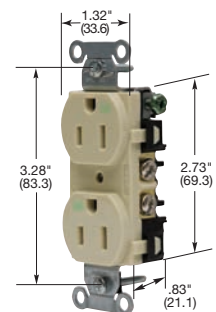

**BR15IWR**

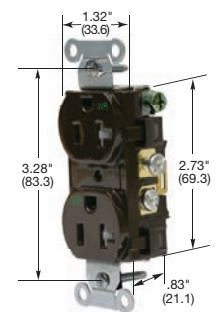

**BR20WRTR**

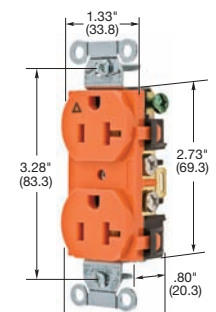

**IG20CR**