




## 15 and 20 Ampere, 125 Volts

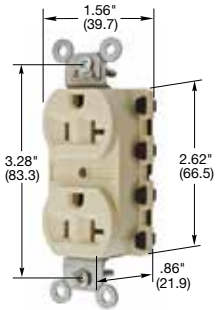


**SNAP53621A**

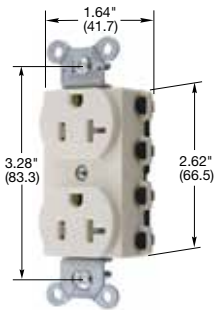


**SNAP5362LATRA**

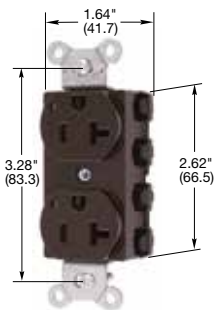

**SNAP5362L**

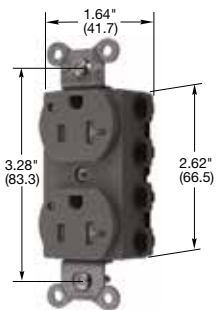

**SNAP5362GYLTRA**

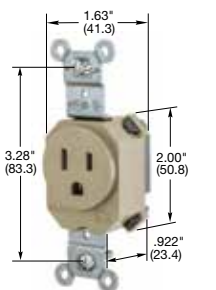

**SNAP52611**

Dimensions in Inches (mm)

### SNAPConnect® Extra Heavy Duty Receptacles

#### Duplex

Description	Color	Catalog Number	Catalog Number	
Specification grade, finder groove, nylon face, modular receptacle which requires pigtailed connector on page A-15.	Black	<b>SNAP5262BKA</b>	<b>SNAP5362BKA</b>	
	Brown	<b>SNAP5262A</b>	<b>SNAP5362A</b>	
	Gray	<b>SNAP5262GYA</b>	<b>SNAP5362GYA</b>	
	Ivory	<b>SNAP5262IA</b>	<b>SNAP5362IA</b>	
	Light Almond	<b>SNAP5262LAA</b>	<b>SNAP5362LAA</b>	
	Red	<b>SNAP5262RA</b>	<b>SNAP5362RA</b>	
Specification grade, smooth, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP5262BKNA</b>	<b>SNAP5362BKNA</b>	
	Brown	<b>SNAP5262NA</b>	<b>SNAP5362NA</b>	
	Gray	<b>SNAP5262GYNA</b>	<b>SNAP5362GYNA</b>	
	Ivory	<b>SNAP5262INA</b>	<b>SNAP5362INA</b>	
	Light Almond	<b>SNAP5262LANA</b>	<b>SNAP5362LANA</b>	
	Red	<b>SNAP5262RNA</b>	<b>SNAP5362RNA</b>	
Specification grade, Tamper-Resistant, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP5262BKTRA</b>	<b>SNAP5362BKTRA</b>	
	Blue	<b>SNAP5262BLTRA</b>	<b>SNAP5362BLTRA</b>	
	Brown	<b>SNAP5262TRA</b>	<b>SNAP5362TRA</b>	
	Gray	<b>SNAP5262GYTRA</b>	<b>SNAP5362GYTRA</b>	
	Ivory	<b>SNAP5262ITRA</b>	<b>SNAP5362ITRA</b>	
	Light Almond	<b>SNAP5262LATRA</b>	<b>SNAP5362LATRA</b>	
Specification grade, Tamper-Resistant, Split Circuit, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP5262BKSTRA</b>	<b>SNAP5362BKSTRA</b>	
	Blue	<b>SNAP5262BLSTRA</b>	<b>SNAP5362BLSTRA</b>	
	Brown	<b>SNAP5262STRA</b>	<b>SNAP5362STRA</b>	
	Gray	<b>SNAP5262GYSTRA</b>	<b>SNAP5362GYSTRA</b>	
	Ivory	<b>SNAP5262ISCTRA</b>	<b>SNAP5362ISCTRA</b>	
	Light Almond	<b>SNAP5262LASCTRA</b>	<b>SNAP5362LASCTRA</b>	
Isolated ground <sup>A</sup> , Specification grade, Tamper-Resistant.	Red	<b>SNAP5262RSTRA</b>	<b>SNAP5362RSTRA</b>	
	White	<b>SNAP5262WSTRA</b>	<b>SNAP5362WSTRA</b>	
	Orange	<b>SNAP5262IGTRA</b>	<b>SNAP5362IGTRA</b>	
	Specification grade, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP5262BKL</b>	<b>SNAP5362BKL</b>
		Blue	<b>SNAP5262BLL</b>	<b>SNAP5362BLL</b>
		Brown	<b>SNAP5262L</b>	<b>SNAP5362L</b>
Gray		<b>SNAP5262GYL</b>	<b>SNAP5362GYL</b>	
Ivory		<b>SNAP5262IL</b>	<b>SNAP5362IL</b>	
Light Almond		<b>SNAP5262LAL</b>	<b>SNAP5362LAL</b>	
Isolated ground <sup>A</sup> , Specification grade, with Power Indicating LED.	Red	<b>SNAP5262RL</b>	<b>SNAP5362RL</b>	
	White	<b>SNAP5262WL</b>	<b>SNAP5362WL</b>	
	Orange	<b>SNAP5262IGL</b>	<b>SNAP5362IGL</b>	
	Specification grade, Tamper-Resistant, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA.	Black	<b>SNAP5262BKLTR</b>	<b>SNAP5362BKLTR</b>
		Blue	<b>SNAP5262BLLTR</b>	<b>SNAP5362BLLTR</b>
		Brown	<b>SNAP5262LTR</b>	<b>SNAP5362LTR</b>
Gray		<b>SNAP5262GYLTR</b>	<b>SNAP5362GYLTR</b>	
Ivory		<b>SNAP5262ILTR</b>	<b>SNAP5362ILTR</b>	
Light Almond		<b>SNAP5262LALTR</b>	<b>SNAP5362LALTR</b>	
Isolated ground <sup>A</sup> , Specification grade, TR with Power Indicating LED.	Red	<b>SNAP5262RLTR</b>	<b>SNAP5362RLTR</b>	
	White	<b>SNAP5262WLTR</b>	<b>SNAP5362WLTR</b>	
	Orange	<b>SNAP5262IGLTR</b>	<b>SNAP5362IGLTR</b>	

### SNAPConnect® Extra Heavy Duty Standard Single Receptacles

Color	Standard Duplex		Standard Duplex Tamper-Resistant	
	15A 125V	20A 125V	15A 125V	20A 125V
Almond	<b>SNAP5261AL</b>	<b>SNAP5361AL</b>	<b>SNAP5261ALTR</b>	<b>SNAP5361ALTR</b>
Black	<b>SNAP5261BK</b>	<b>SNAP5361BK</b>	<b>SNAP5261BKTR</b>	<b>SNAP5361BKTR</b>
Blue	<b>SNAP5261BL</b>	<b>SNAP5361BL</b>	<b>SNAP5261BLTR</b>	<b>SNAP5361BLTR</b>
Brown	<b>SNAP5261</b>	<b>SNAP5361</b>	<b>SNAP5261TR</b>	<b>SNAP5361TR</b>
Gray	<b>SNAP5261GY</b>	<b>SNAP5361GY</b>	<b>SNAP5261GYTR</b>	<b>SNAP5361GYTR</b>
Ivory	<b>SNAP5261I</b>	<b>SNAP5361I</b>	<b>SNAP5261ITR</b>	<b>SNAP5361ITR</b>
Light Almond	<b>SNAP5261LA</b>	<b>SNAP5361LA</b>	<b>SNAP5261LATR</b>	<b>SNAP5361LATR</b>
Red	<b>SNAP5261R</b>	<b>SNAP5361R</b>	<b>SNAP5261RTR</b>	<b>SNAP5361RTR</b>
White	<b>SNAP5261W</b>	<b>SNAP5361W</b>	<b>SNAP5261WTR</b>	<b>SNAP5361WTR</b>