 
 


# Straight Blade Devices








15 and 20 Ampere, 125 Volts



## SNAPConnect® Extra Heavy Duty Receptacles

### Style Line® Decorator

Description	Color	Catalog Number	
Specification grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below.	Black	<b>SNAP2152BKA</b>	<b>SNAP2162BKA</b>
	Brown	<b>SNAP2152A</b>	<b>SNAP2162A</b>
	Gray	<b>SNAP2152GYA</b>	<b>SNAP2162GYA</b>
	Ivory	<b>SNAP2152IA</b>	<b>SNAP2162IA</b>
	Light Almond	<b>SNAP2152LAA</b>	<b>SNAP2162LAA</b>
	Red	<b>SNAP2152RA</b>	<b>SNAP2162RA</b>
Specification grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	White	<b>SNAP2152WA</b>	<b>SNAP2162WA</b>
	Black	<b>SNAP2152BKNA</b>	<b>SNAP2162BKNA</b>
	Brown	<b>SNAP2152NA</b>	<b>SNAP2162NA</b>
	Gray	<b>SNAP2152GYNA</b>	<b>SNAP2162GYNA</b>
	Ivory	<b>SNAP2152INA</b>	<b>SNAP2162INA</b>
	Light Almond	<b>SNAP2152LANA</b>	<b>SNAP2162LANA</b>
Specification grade, Tamper-Resistant, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Red	<b>SNAP2152RNA</b>	<b>SNAP2162RNA</b>
	White	<b>SNAP2152WNA</b>	<b>SNAP2162WNA</b>
	Black	<b>SNAP2152BKTRA</b>	<b>SNAP2162BKTRA</b>
	Blue	<b>SNAP2152BLTRA</b>	<b>SNAP2162BLTRA</b>
	Brown	<b>SNAP2152TRA</b>	<b>SNAP2162TRA</b>
	Gray	<b>SNAP2152GYTRA</b>	<b>SNAP2162GYTRA</b>
Specification grade, Tamper-Resistant, Split Circuit, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Ivory	<b>SNAP2152ITRA</b>	<b>SNAP2162ITRA</b>
	Light Almond	<b>SNAP2152LATRA</b>	<b>SNAP2162LATRA</b>
	Red	<b>SNAP2152RTRA</b>	<b>SNAP2162RTRA</b>
	White	<b>SNAP2152WTRA</b>	<b>SNAP2162WTRA</b>
	Black	<b>SNAP2152BKSCTRA</b>	<b>SNAP2162BKSCTRA</b>
	Blue	<b>SNAP2152BLSCTRA</b>	<b>SNAP2162BLSCTRA</b>
Isolated ground <sup>A</sup> , Specification grade, Tamper-Resistant.	Brown	<b>SNAP2152SCTRA</b>	<b>SNAP2162SCTRA</b>
	Gray	<b>SNAP2152GYSCTRA</b>	<b>SNAP2162GYSCTRA</b>
	Ivory	<b>SNAP2152ISCTRA</b>	<b>SNAP2162ISCTRA</b>
	Light Almond	<b>SNAP2152LASCTRA</b>	<b>SNAP2162LASCTRA</b>
	Red	<b>SNAP2152RSCTRA</b>	<b>SNAP2162RSCTRA</b>
	White	<b>SNAP2152WSCTRA</b>	<b>SNAP2162WSCTRA</b>
Isolated ground <sup>A</sup> , Specification grade, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Orange	<b>SNAP2152IGTRA</b>	<b>SNAP2162IGTRA</b>
	Black	<b>SNAP2152BKL</b>	<b>SNAP2162BKL</b>
	Blue	<b>SNAP2152BLL</b>	<b>SNAP2162BLL</b>
	Brown	<b>SNAP2152L</b>	<b>SNAP2162L</b>
	Gray	<b>SNAP2152GYL</b>	<b>SNAP2162GYL</b>
	Ivory	<b>SNAP2152IL</b>	<b>SNAP2162IL</b>
Isolated ground <sup>A</sup> , Specification grade, with Power Indicating LED.	Light Almond	<b>SNAP2152LAL</b>	<b>SNAP2162LAL</b>
	Red	<b>SNAP2152RL</b>	<b>SNAP2162RL</b>
	White	<b>SNAP2152WL</b>	<b>SNAP2162WL</b>
	Black	<b>SNAP2152BKLTRA</b>	<b>SNAP2162BKLTRA</b>
	Blue	<b>SNAP2152BLLTRA</b>	<b>SNAP2162BLLTRA</b>
	Brown	<b>SNAP2152LTRA</b>	<b>SNAP2162LTRA</b>
Specification grade, Tamper-Resistant, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Gray	<b>SNAP2152GYLTRA</b>	<b>SNAP2162GYLTRA</b>
	Ivory	<b>SNAP2152ILTRA</b>	<b>SNAP2162ILTRA</b>
	Light Almond	<b>SNAP2152LALTRA</b>	<b>SNAP2162LALTRA</b>
	Red	<b>SNAP2152RLTRA</b>	<b>SNAP2162RLTRA</b>
	White	<b>SNAP2152WLTRA</b>	<b>SNAP2162WLTRA</b>
	Isolated ground <sup>A</sup> , Specification grade, TR with Power Indicating LED.	Orange	<b>SNAP2152IGLTRA</b>

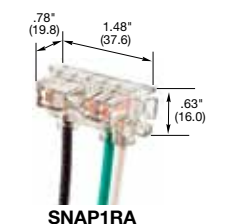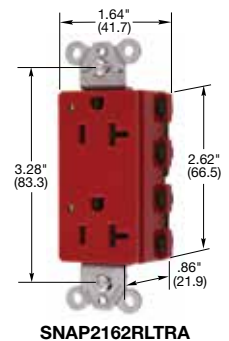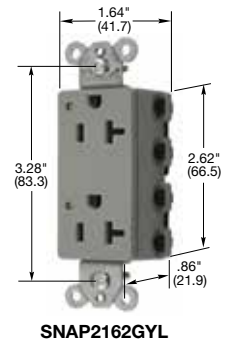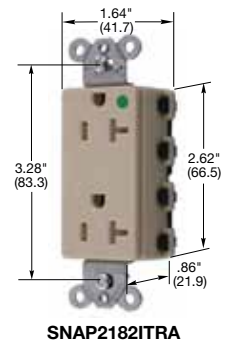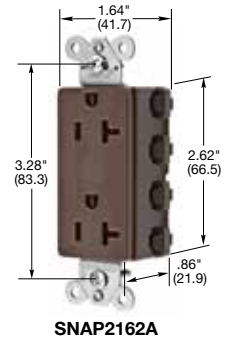

Note: <sup>A</sup>See section M additional information on isolated ground devices.  
See page Tech-10 for Tamper-Resistant and LED Power Indicators descriptions.  
See pages A-47 and A-48 for accessories.  
See section N for wallplates.

## SNAPConnect® Right Angle Pigtailed Connector

Description	Wire Type	General Use	Assembled in USA
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material.	Solid	<b>SNAP1RA</b>	<b>SNAP1RNA</b>
	Stranded	<b>SNAP2RA</b>	<b>SNAP2RNA</b>

Note: For Assembled in USA products, must order connector with NA suffix.

Dimensions in Inches (mm)