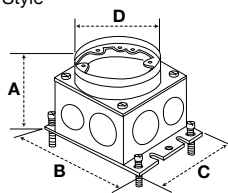


Flush Round Single Service Metal Floor Boxes, for Use In Concrete Floors

Dimensions Inches (mm)

Style	Cast Iron					Stamped Steel		
								
 Collar Material: Brass Aluminum	B2536 BA2536	B253641 BA253641	B2503 BA2503	B2506 BA2506	B2506415 BA2506415	B2537 BA2537	B2527 BA2527	B2529 BA2529
Min. Depth of Pour	3.25" (82.6)	3.75" (95.3)	4.75" (120.7)	3.00" (76.2)	4.00" (101.6)	3.00" (76.2)		
Adjustability	Fully	Fully	Fully	Fully	Fully	Fully		
Before Pour External Height Adjustment	1.25" (31.8)	—	—	—	1.25" (31.8)	1.25" (31.8)		
After Pour Internal Height Adjustment	.38" (9.5)	.63" (15.9)	.63" (15.9)	.38" (9.5)	.38" (9.5)	.38" (9.5)		
Cubic Inch (cm3) Capacity	33.0 cu. in. (540.7 cm3)	36.0 cu. in. (590.0 cm3)	50.8 cu. in. (832.5 cm3)	30.0 cu. in. (491.6 cm3)	54.0 cu. in. (884.9 cm3)	37.3 cu. in. (611.2 cm3)		
Dimensions – A	3.05" (77.5)	3.75" (95.3)	4.75" (120.7)	2.87" (72.9)	3.88" (98.6)	2.91" (73.9)		
Dimensions – B	4.84" (122.9)	5.00" (127.0)	5.00" (127.0)	4.84" (122.9)	6.00" (152.4)	6.00" (152.4)		
Dimensions – C	4.84" (122.9)	4.63" (117.6)	4.66" (118.4)	4.84" (122.9)	4.81" (122.2)	4.81" (122.2)		
Dimensions – D	4.19" (106.4)	4.19" (106.4)	4.19" (106.4)	4.19" (106.4)	4.19" (106.4)	4.19" (106.4)		
Threaded Access Holes	(4) ¾" (4) 1"	(4) ¾"	(4) 1¼" (4) 1½"	(4) ¾"	—	—		
Knockouts – Sides	—	—	—	—	(1) 1" & (1) ¾"	(2) ½" & (1) ¾"		
Knockouts – Ends	—	—	—	—	(1) 1¼" & (1) ½"	(1) ½" & (1) ¾"		
Knockouts – Bottom	—	—	—	—	(3) ½" & (2) ¾"	(3) ½" & (2) ¾"		
Concrete Cover Included	✓	✓	✓	✓	✓	✓		
Closure Plugs Included	✓	✓	✓	✓	—	—		

Note: UL File Number E31999.

CSA File Number LR18416.

Suitable for single service applications only.

Single Service Covers

Brass
Aluminum
3.88 in. Dia.

S3925
SA3925



Duplex
Flap

S3725
SA3725



Duplex
Screw

S2525
SA2525



2 1/8" x 3/4"
Combination

S2725
SA2725



2 1/8" x 1"
Combination

S2925
SA2925



2 1/8" Single
Receptacle

S3525
—



2 3/8" Single
Receptacle

S3325
—



2 1/8" Single
Receptacle
(Terrazzo Floor)

Carpet Flanges

5.25 in. Dia.

S3182



Brass

SA3182



Brushed
Aluminum

S3079



Clear
Polycarbonate

6.25 in. Dia.

S3082



Brass

SA3082



Brushed
Aluminum

One Piece Brass Cover and Carpet Flange

Brass
Aluminum
6.25 in. Dia.

SF3925
SFA3925



Duplex
Flap

SF2525
—



2 1/8" x 3/4"
Combination

SF2725
—



2 1/8" x 1"
Combination

SF2925
—



2 1/8" Single
Receptacle

Dimensions in Inches (mm)