




15 and 20 Ampere, 125 Volts

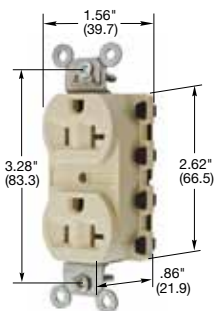


SNAP53621A

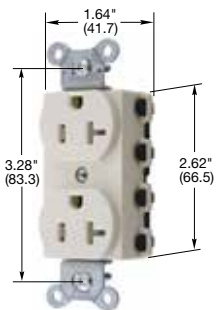


SNAP5362LATRA

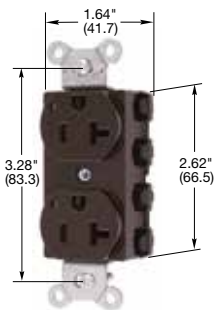

SNAP5362L

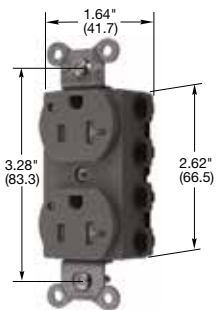

SNAP5362GYLTRA

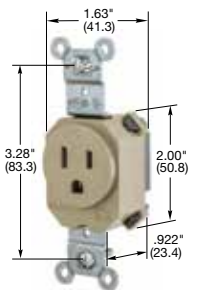

SNAP52611

Dimensions in Inches (mm)

SNAPConnect® Extra Heavy Duty Receptacles

Duplex

| Description | Color | Catalog Number | Catalog Number | |
|--|--|------------------------|------------------------|-----------------------|
| Specification grade, finder groove, nylon face, modular receptacle which requires pigtailed connector on page A-15. | Black | SNAP5262BKA | SNAP5362BKA | |
| | Brown | SNAP5262A | SNAP5362A | |
| | Gray | SNAP5262GYA | SNAP5362GYA | |
| | Ivory | SNAP5262IA | SNAP5362IA | |
| | Light Almond | SNAP5262LAA | SNAP5362LAA | |
| | Red | SNAP5262RA | SNAP5362RA | |
| Specification grade, smooth, nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA. | Black | SNAP5262BKNA | SNAP5362BKNA | |
| | Brown | SNAP5262NA | SNAP5362NA | |
| | Gray | SNAP5262GYNA | SNAP5362GYNA | |
| | Ivory | SNAP5262INA | SNAP5362INA | |
| | Light Almond | SNAP5262LANA | SNAP5362LANA | |
| | Red | SNAP5262RNA | SNAP5362RNA | |
| Specification grade, Tamper-Resistant, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA. | Black | SNAP5262BKTRA | SNAP5362BKTRA | |
| | Blue | SNAP5262BLTRA | SNAP5362BLTRA | |
| | Brown | SNAP5262TRA | SNAP5362TRA | |
| | Gray | SNAP5262GYTRA | SNAP5362GYTRA | |
| | Ivory | SNAP5262ITRA | SNAP5362ITRA | |
| | Light Almond | SNAP5262LATRA | SNAP5362LATRA | |
| Specification grade, Tamper-Resistant, Split Circuit, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA. | Black | SNAP5262BKSTRA | SNAP5362BKSTRA | |
| | Blue | SNAP5262BLSTRA | SNAP5362BLSTRA | |
| | Brown | SNAP5262STRA | SNAP5362STRA | |
| | Gray | SNAP5262GYSTRA | SNAP5362GYSTRA | |
| | Ivory | SNAP5262ISCTRA | SNAP5362ISCTRA | |
| | Light Almond | SNAP5262LASCTRA | SNAP5362LASCTRA | |
| Isolated ground ^A , Specification grade, Tamper-Resistant. | Red | SNAP5262RSTRA | SNAP5362RSTRA | |
| | White | SNAP5262WSTRA | SNAP5362WSTRA | |
| | Orange | SNAP5262IGTRA | SNAP5362IGTRA | |
| | Specification grade, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA. | Black | SNAP5262BKL | SNAP5362BKL |
| | | Blue | SNAP5262BLL | SNAP5362BLL |
| | | Brown | SNAP5262L | SNAP5362L |
| Gray | | SNAP5262GYL | SNAP5362GYL | |
| Ivory | | SNAP5262IL | SNAP5362IL | |
| Light Almond | | SNAP5262LAL | SNAP5362LAL | |
| Isolated ground ^A , Specification grade, with Power Indicating LED. | Red | SNAP5262RL | SNAP5362RL | |
| | White | SNAP5262WL | SNAP5362WL | |
| | Orange | SNAP5262IGL | SNAP5362IGL | |
| | Specification grade, Tamper-Resistant, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page A-15. Assembled in USA. | Black | SNAP5262BKLTRA | SNAP5362BKLTRA |
| | | Blue | SNAP5262BLLTRA | SNAP5362BLLTRA |
| | | Brown | SNAP5262LTRA | SNAP5362LTRA |
| Gray | | SNAP5262GYLTRA | SNAP5362GYLTRA | |
| Ivory | | SNAP5262ILTRA | SNAP5362ILTRA | |
| Light Almond | | SNAP5262LALTRA | SNAP5362LALTRA | |
| Isolated ground ^A , Specification grade, TR with Power Indicating LED. | Red | SNAP5262RLTRA | SNAP5362RLTRA | |
| | White | SNAP5262WLTRA | SNAP5362WLTRA | |
| | Orange | SNAP5262IGLTRA | SNAP5362IGLTRA | |

SNAPConnect® Extra Heavy Duty Standard Single Receptacles

| Color | Standard Duplex | | Standard Duplex Tamper-Resistant | |
|--------------|-------------------|-------------------|----------------------------------|---------------------|
| | 15A 125V | 20A 125V | 15A 125V | 20A 125V |
| Almond | SNAP5261AL | SNAP5361AL | SNAP5261ALTR | SNAP5361ALTR |
| Black | SNAP5261BK | SNAP5361BK | SNAP5261BKTR | SNAP5361BKTR |
| Blue | SNAP5261BL | SNAP5361BL | SNAP5261BLTR | SNAP5361BLTR |
| Brown | SNAP5261 | SNAP5361 | SNAP5261TR | SNAP5361TR |
| Gray | SNAP5261GY | SNAP5361GY | SNAP5261GYTR | SNAP5361GYTR |
| Ivory | SNAP5261I | SNAP5361I | SNAP5261ITR | SNAP5361ITR |
| Light Almond | SNAP5261LA | SNAP5361LA | SNAP5261LATR | SNAP5361LATR |
| Red | SNAP5261R | SNAP5361R | SNAP5261RTR | SNAP5361RTR |
| White | SNAP5261W | SNAP5361W | SNAP5261WTR | SNAP5361WTR |