 



# Straight Blade Devices

15 and 20 Ampere, 125 Volts



## SNAPConnect® GFCI LED


Description	Color	Catalog Number	
SNAPConnect GFCI LED, self-grounding staple, requires connector below, sold separately. Add "NA" suffix for devices Assembled in USA.	Almond	<b>GFRST15SNAPAL</b>	<b>GFRST20SNAPAL</b>
	Black	<b>GFRST15SNAPBK</b>	<b>GFRST20SNAPBK</b>
	Brown	<b>GFRST15SNAP</b>	<b>GFRST20SNAP</b>
	Gray	<b>GFRST15SNAPGY</b>	<b>GFRST20SNAPGY</b>
	Ivory	<b>GFRST15SNAPI</b>	<b>GFRST20SNAPI</b>
	Light Almond	<b>GFRST15SNAPLA</b>	<b>GFRST20SNAPLA</b>
	Red	<b>GFRST15SNAPR</b>	<b>GFRST20SNAPR</b>
	White	<b>GFRST15SNAPW</b>	<b>GFRST20SNAPW</b>

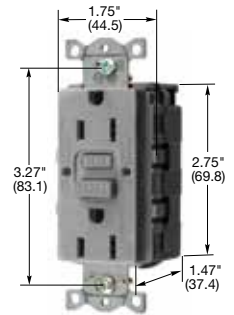

**GFRST15SNAPGY**



## SNAPConnect® GFCI LED, Tamper and Weather Resistant

Description	Color	Catalog Number	
SNAPConnect GFCI TR/WR, self-grounding staple, requires connector below, sold separately. Add "NA" suffix for devices Assembled in USA.	Almond	<b>GFTWRST15SNAPAL</b>	<b>GFTWRST20SNAPAL</b>
	Black	<b>GFTWRST15SNAPBK</b>	<b>GFTWRST20SNAPBK</b>
	Brown	<b>GFTWRST15SNAP</b>	<b>GFTWRST20SNAP</b>
	Gray	<b>GFTWRST15SNAPGY</b>	<b>GFTWRST20SNAPGY</b>
	Ivory	<b>GFTWRST15SNAPI</b>	<b>GFTWRST20SNAPI</b>
	Light Almond	<b>GFTWRST15SNAPLA</b>	<b>GFTWRST20SNAPLA</b>
	Red	<b>GFTWRST15SNAPR</b>	<b>GFTWRST20SNAPR</b>
	White	<b>GFTWRST15SNAPW</b>	<b>GFTWRST20SNAPW</b>

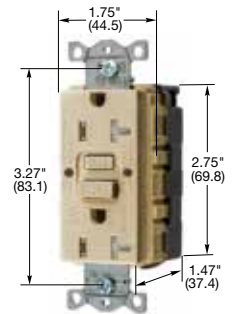


**GFTWRST20SNAPI**

  Note: GFCI type receptacles should not be used in critical care patient areas or for electrical life support equipment applications because of the possibility of power interruption. All GFCI receptacles are furnished with a matching color nylon wallplate, 20 amp feed-through capability.





## SNAPConnect® USB Charger, Duplex Receptacles

Description	Color	Catalog Number	
SNAPConnect USB Charger, Tamper-Resistant Style Line® decorator duplex receptacle, two USB type 2.0 ports 3 Amp, 5 Volt DC, 15 or 20 Amp, 125 Volt AC.	Black	<b>SNAP15USBBK</b>	<b>SNAP20USBBK</b>
	Brown	<b>SNAP15USB</b>	<b>SNAP20USB</b>
	Gray	<b>SNAP15USBGY</b>	<b>SNAP20USBGY</b>
	Ivory	<b>SNAP15USBI</b>	<b>SNAP20USBI</b>
	Light Almond	<b>SNAP15USBLA</b>	<b>SNAP20USBLA</b>
	White	<b>SNAP15USBW</b>	<b>SNAP20USBW</b>

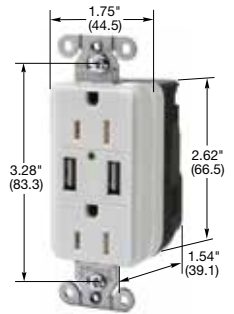


**SNAP15USBW**

  

## SNAPConnect® Surge Protection, Tamper-Resistant Receptacle with Power Indicating LED

Description	Color	Catalog Number	
SNAPConnect Surge suppression, Tamper-Resistant, smooth face, duplex receptacle.	Blue	<b>SNAP5262S</b>	<b>SNAP5362S</b>
	Gray	<b>SNAP5262GYS</b>	<b>SNAP5362GYS</b>
	Ivory	<b>SNAP5262IS</b>	<b>SNAP5362IS</b>
	Light Almond	<b>SNAP5262LAS</b>	<b>SNAP5362LAS</b>
	White	<b>SNAP5262WS</b>	<b>SNAP5362WS</b>

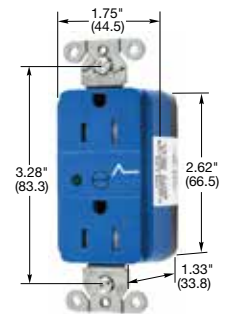


**SNAP5262S**

## SNAPConnect® Tester

Description	Catalog Number
Circuit Tester for SNAPConnect receptacle terminals, GFCI and standard receptacles.	<b>SNAPCTG</b>

Note: See page Tech-10 for Tamper-Resistant, Weather Resistant and LED Power Indicators descriptions.

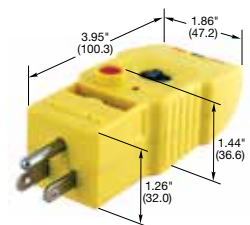

**SNAPCTG**

Dimensions in Inches (mm)