

**30 Amp, 3ØY 120/208, 277/480 and 347/600 Volts AC  
4 Pole, 5 Wire, Grounding**



**HBL2811SW**




**HBL2811S**



**HBL2811**



**HBL2815SW**

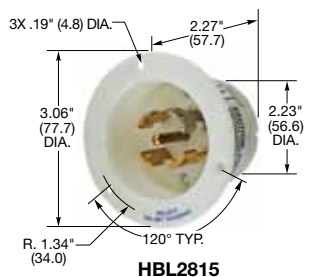

**HBL2815**

Dimensions in Inches (mm)



**30A 3ØY  
120/208V AC  
NEMA L21-30P  
3 HP**



**30A 3ØY  
240/415V AC  
NEMA L26-30P**



**30A 3ØY  
277/480V AC  
NEMA L22-30P  
10 HP**



**30A 3ØY  
347/600V AC  
NEMA L23-30P**

## Plugs

### Watertight Safety-Shroud®

IP66 SUITABILITY

UL Type 4x, 12

Description	Cord Dia.	Catalog Number			
Black Valox® housing, white Valox® clamps.	.350"-1.150" (9-29)	<b>HBL2811SW</b>	<b>HBL2801</b>	<b>HBL2821SW</b>	<b>HBL2831SW</b>

### Safety-Shroud®

IP20 SUITABILITY

Description	Cord Dia.	Catalog Number			
Black and white nylon body, white Valox® shroud. Can be used with the Insulgrip Connector Bodies.	.350"-1.150" (9-29)	<b>HBL2811S</b>	-	-	-

Note: See page B-40 for accessories.

### Insulgrip®

IP20 SUITABILITY

Description	Cord Dia.	Catalog Number			
Black and white nylon.	.350"-1.150" (9-29)	<b>HBL2811</b>	-	<b>HBL2821</b>	<b>HBL2831</b>
Corrosion resistant, yellow nylon.	.350"-1.150" (9-29)	<b>HBL28CM11</b>	-	-	-
Black and white for flat cable.	.350"-1.150" (9-29)	<b>HBL2811FC</b>	-	-	-
All black nylon.	.350"-1.150" (9-29)	<b>HBL2811BK</b>	-	-	-

Note: See page B-52 for accessories.

## Flanged Inlets

### Watertight Safety-Shroud®

IP66 SUITABILITY

UL Type 4x, 12

Description	Catalog Number		
Gray Valox® housing and flange.	<b>HBL2815SW</b>	<b>HBL2805</b>	-

Note: See page B-54 for accessories.

### Insulgrip®

IP20 SUITABILITY

Description	Catalog Number			
Nylon casing, back wired.	<b>HBL2815</b>	-	<b>HBL2825</b>	<b>HBL2835</b>

Note: See page B-52 for accessories.

See pages B-69 and B-70 for technical information on Twist-Lock and Watertight Safety-Shroud devices.

## Twist-Lock® 3-Phase Circuit Tester



Description	Rating	Catalog Number			
3-Phase Circuit Tester	3Ø 120/208V AC Min. Voltage: 90V AC	<b>HBL3PT2811</b>	-	-	-

Note: Testers in other NEMA configurations can be developed upon request.

See page B-53 for additional circuit testers.



**HBL3PT2811**

**HBLMITL** - For use with Watertight Safety-Shroud receptacles, see page B-41.



Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.