



## Maintained Contact Toggle, Specification Grade, 5A, 24V DC

Description	Toggle Color	Single Pole	Double Pole	Three Way	Four Way
Nylon toggle, back and side wired.	Almond	<b>CSB120ALLV</b>	—	<b>CSB320ALLV</b>	—
	Black	<b>CSB120BKLV</b>	—	<b>CSB320BKLV</b>	—
	Brown	<b>CSB120BRLV</b>	—	<b>CSB320BRLV</b>	—
	Gray	<b>CSB120GYLV</b>	—	<b>CSB320GYLV</b>	—
	Ivory	<b>CSB120ILV</b>	—	<b>CSB320ILV</b>	—
	Light Almond	<b>CSB120LALV</b>	—	<b>CSB320LALV</b>	—
	Red	<b>CSB120RLV</b>	—	<b>CSB320RLV</b>	—
	White	<b>CSB120WHLV</b>	—	<b>CSB320WHLV</b>	—

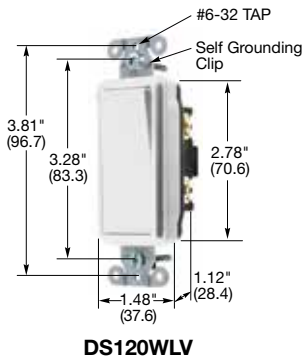

## Maintained Contact Decorator, Specification Grade, 5A, 24V DC

Description	Toggle Color	Single Pole	Double Pole	Three Way	Four Way
Nylon decorator, back and side wired.	Almond	<b>DS120ALLV</b>	—	<b>DS320ALLV</b>	—
	Black	<b>DS120BKLV</b>	—	<b>DS320BKLV</b>	—
	Brown	<b>DS120LV</b>	—	<b>DS320LV</b>	—
	Gray	<b>DS120GYLV</b>	—	<b>DS320GYLV</b>	—
	Ivory	<b>DS120ILV</b>	—	<b>DS320ILV</b>	—
	Light Almond	<b>DS120LALV</b>	—	<b>DS320LALV</b>	—
	Red	<b>DS120RLV</b>	—	<b>DS320RLV</b>	—
	White	<b>DS120WLV</b>	—	<b>DS320WLV</b>	—

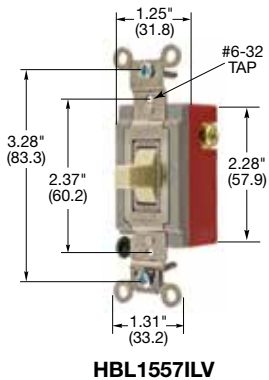

## Momentary Contact, Specification Grade, Single Pole, Double Throw, Center OFF 5A, 24V DC

Description	Toggle Color	Single Pole	Double Pole	Three Way	Four Way
Nylon toggle, back and side wired.	Brown	<b>HBL1557LV</b>	—	—	—
	Gray	<b>HBL1557GYLV</b>	—	—	—
	Ivory	<b>HBL1557ILV</b>	—	—	—
	Red	<b>HBL1557RLV</b>	—	—	—
	White	<b>HBL1557WLV</b>	—	—	—

Note: See page D-13 for pre-wired/leaded devices.  
See page D-15 for accessories and page D-16 for wallplates.  
See page D-22 for technical information.

### HP Conversion Chart

	120V	208V	240V	277V AC
15A	.5HP	1.5HP	2HP	2HP
20A	1HP	2HP	2HP	2HP

Dimensions in Inches (mm)