


## Features and Benefits


### Heavy Duty Commercial Standard GFCI Receptacles

- Patented AUTOGUARD® self test technology includes disconnecting power to the receptacle if critical components are damaged and GFCI protection is lost
- Internal back wiring clamp and guide for quick and secure termination
- Night light option includes light sensor controls for automatic ON and OFF, custom dual lens for optimum light output

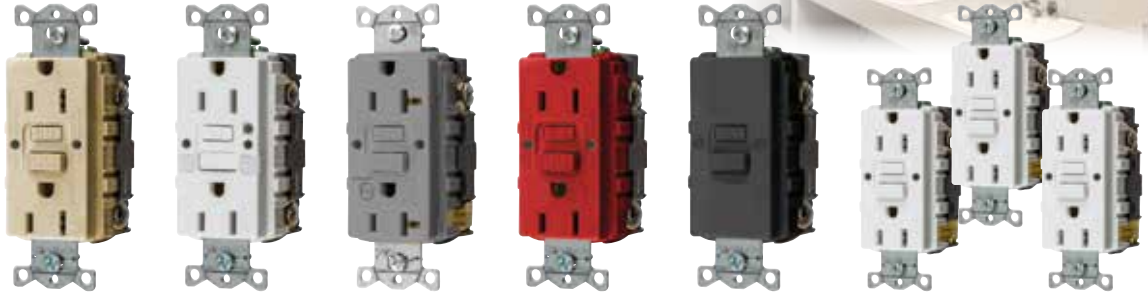

### Standard

Rating	Color	Standard	Night Light Two LED Night Lights	Alarm	Assembled in USA	Blank Face Available in 20A Only	Standard 3-Pack Three Devices per Pack	
	Almond	GFRST15AL	GFRST15ALNL	GFRST15ALB	GFRST15ALU	—	—	
	Black	GFRST15BK	GFRST15BKNL	GFRST15BKB	GFRST15BKU	—	—	
	Brown	GFRST15	GFRST15NL	GFRST15B	GFRST15U	—	—	
	Gray	GFRST15GY	GFRST15GYNL	GFRST15GYB	GFRST15GYU	—	—	
	Ivory	GFRST15I	GFRST15INL	GFRST15IB	GFRST15IU	—	GFRST15I3	
	Light Almond	GFRST15LA	GFRST15LANL	GFRST15LAB	GFRST15LAU	—	GFRST15LA3	
	Red	GFRST15R	GFRST15RNL	GFRST15RB	GFRST15RU	—	—	
	White	GFRST15W	GFRST15WNL	GFRST15WZB	GFRST15WU	—	GFRST15W3	
		Almond	GFRST20AL	GFRST20ALNL	GFRST20ALB	GFRST20ALU	GFBFST20AL	—
		Black	GFRST20BK	GFRST20BKNL	GFRST20BKB	GFRST20BKU	GFBFST20BK	—
Brown		GFRST20	GFRST20NL	GFRST20B	GFRST20U	GFBFST20	—	
Gray		GFRST20GY	GFRST20GYNL	GFRST20GYB	GFRST20GYU	GFBFST20GY	—	
Ivory		GFRST20I	GFRST20INL	GFRST20IB	GFRST20IU	GFBFST20I	GFRST20I3	
Light Almond		GFRST20LA	GFRST20LANL	GFRST20LAB	GFRST20LAU	GFBFST20LA	GFRST20LA3	
Red		GFRST20R	GFRST20RNL	GFRST20RB	GFRST20RU	GFBFST20R	—	
White		GFRST20W	GFRST20WNL	GFRST20WB	GFRST20WU	GFBFST20W	GFRST20W3	

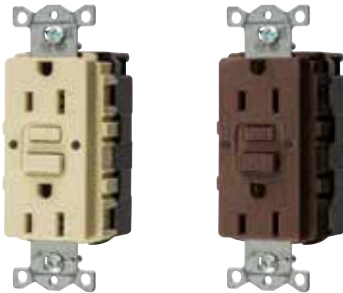

### Standard SNAPConnect®

Rating	Color	Standard	Assembled in USA
	Almond	GFRST15SNAPAL	GFRST15SNAPALNA
	Black	GFRST15SNAPBK	GFRST15SNAPBKNA
	Brown	GFRST15SNAP	GFRST15SNAPNA
	Gray	GFRST15SNAPGY	GFRST15SNAPGYNA
	Ivory	GFRST15SNAPI	GFRST15SNAPINA
	Light Almond	GFRST15SNAPLA	GFRST15SNAPLANA
	Red	GFRST15SNAPR	GFRST15SNAPRNA
	Almond	GFRST20SNAPAL	GFRST20SNAPALNA
	Black	GFRST20SNAPBK	GFRST20SNAPBKNA
	Brown	GFRST20SNAP	GFRST20SNAPNA
	Gray	GFRST20SNAPGY	GFRST20SNAPGYNA
	Ivory	GFRST20SNAPI	GFRST20SNAPINA
	Light Almond	GFRST20SNAPLA	GFRST20SNAPLANA
	Red	GFRST20SNAPR	GFRST20SNAPRNA
White	GFRST20SNAPW	GFRST20SNAPWNA	

### Right Angle Pigtailed Terminal



Description	Type	Catalog Number
Clear right angle terminal with 6 inch leads, 600V, #12 AWG THHN/THWN-2, Polycarbonate housing material.	Solid Stranded	<b>SNAP1RA</b> <b>SNAP2RA</b>
Same as above. Assembled in USA.	Solid Stranded	<b>SNAP1RANA</b> <b>SNAP2RANA</b>

Note: GFCI type receptacles should not be used in critical care patient areas or for electrical life support equipment applications because of the possibility of power interruption. All GFCI receptacles are furnished with a matching color nylon wallplate, 20 amp feed-through capability.