


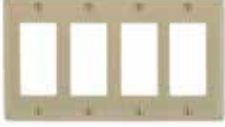




## GFCI, Surge Receptacles and Style Line® Device Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Nylon Jumbo	Material	Metal Catalog Number	
 1-Gang, 1-Decorator	Almond	<b>NP26AL</b>	<b>NPJ26AL</b>	-	Aluminum	①	
	Black	<b>NP26BK</b>	<b>NPJ26BK</b>	-	Brass	<b>SB26</b>	
	Blue	-	<b>NPJ26BL</b>	-	Brass Plated	<b>SBP26</b>	
	Brown	<b>NP26</b>	<b>NPJ26</b>	-	Chrome	<b>SCH26</b>	
	Gray	<b>NP26GY</b>	<b>NPJ26GY</b>	-	S/S 302/304	<b>SS26</b>	
	Ivory	<b>NP26I</b>	<b>NPJ26I</b>	<b>NPJJ26I</b>	S/S 430	<b>SS26L</b>	
	Light Almond	<b>NP26LA</b>	<b>NPJ26LA</b>	<b>NPJJ26LA</b>	Steel, Almond	<b>PHPS1AL*</b>	
	Office White	<b>NP26OW</b>	<b>NPJ26OW</b>	-	Steel, Gray	<b>PHPS1G*</b>	
	Red	<b>NP26R</b>	<b>NPJ26R</b>	-			
	White	<b>NP26W</b>	<b>NPJ26W</b>	<b>NPJJ26W</b>			
	 2-Gang, 2-Decorator	Almond	<b>NP262AL</b>	<b>NPJ262AL</b>	-	Aluminum	①
Black		<b>NP262BK</b>	<b>NPJ262BK</b>	-	Brass	<b>SB262</b>	
Brown		<b>NP262</b>	<b>NPJ262</b>	-	Brass Plated	<b>SBP262</b>	
Gray		<b>NP262GY</b>	<b>NPJ262GY</b>	-	Chrome	<b>SCH262</b>	
Ivory		<b>NP262I</b>	<b>NPJ262I</b>	-	S/S 302/304	<b>SS262</b>	
Light Almond		<b>NP262LA</b>	<b>NPJ262LA</b>	-	S/S 430	<b>SS262L</b>	
Office White		<b>NP262OW</b>	<b>NPJ262OW</b>	-	Steel, Almond	<b>PHPS2AL*</b>	
Red		<b>NP262R</b>	<b>NPJ262R</b>	-	Steel, Gray	<b>PHPS2G*</b>	
White		<b>NP262W</b>	<b>NPJ262W</b>	-			
 3-Gang, 3-Decorator		Almond	<b>NP263AL</b>	<b>NPJ263AL</b>	-	Aluminum	①
		Black	<b>NP263BK</b>	<b>NPJ263BK</b>	-	Brass	①
	Brown	<b>NP263</b>	<b>NPJ263</b>	-	Brass Plated	<b>SBP263</b>	
	Gray	<b>NP263GY</b>	<b>NPJ263GY</b>	-	Chrome	①	
	Ivory	<b>NP263I</b>	<b>NPJ263I</b>	-	S/S 302/304	<b>SS263</b>	
	Light Almond	<b>NP263LA</b>	<b>NPJ263LA</b>	-	S/S 430	-	
	Office White	<b>NP263OW</b>	-	-	Steel, Almond	<b>PHPS3AL*</b>	
	Red	<b>NP263R</b>	-	-			
	White	<b>NP263W</b>	<b>NPJ263W</b>	-			
	 4-Gang, 4-Decorator	Almond	<b>NP264AL</b>	<b>NPJ264AL</b>	-	Aluminum	①
		Black	<b>NP264BK</b>	<b>NPJ264BK</b>	-	Brass	①
Brown		<b>NP264</b>	<b>NPJ264</b>	-	Brass Plated	①	
Gray		<b>NP264GY</b>	<b>NPJ264GY</b>	-	Chrome	①	
Ivory		<b>NP264I</b>	<b>NPJ264I</b>	-	S/S 302/304	<b>SS264</b>	
Light Almond		<b>NP264LA</b>	<b>NPJ264LA</b>	-	S/S 430	-	
Office White		<b>NP264OW</b>	-	-	Steel, Almond	<b>PHPS4AL*</b>	
White		<b>NP264W</b>	<b>NPJ264W</b>	-			
 5-Gang, 5-Decorator		Black	<b>NP265BK</b>	-	-	Aluminum	①
		Brown	<b>NP265</b>	-	-	Brass	①
		Gray	<b>NP265GY</b>	-	-	Brass Plated	①
	Ivory	<b>NP265I</b>	-	-	Chrome	①	
	Light Almond	<b>NP265LA</b>	-	-	S/S 302/304	<b>SS265</b>	
	White	<b>NP265W</b>	-	-	S/S 430	-	
					Steel, Almond	<b>PHPS5AL*</b>	
 6-Gang, 6-Decorator	Black	<b>NP266BK</b>	-	-	Aluminum	①	
	Brown	<b>NP266</b>	-	-	Brass	①	
	Gray	<b>NP266GY</b>	-	-	Brass Plated	①	
	Ivory	<b>NP266I</b>	-	-	Chrome	①	
	Light Almond	<b>NP266LA</b>	-	-	S/S 302/304	<b>SS266</b>	
	White	<b>NP266W</b>	-	-	S/S 430	-	
					Steel, Almond	<b>PHPS6AL*</b>	

Note: All nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

①vA available as a custom wallplate, see pages N-31 to N-34. Consult custom wallplates section for additional openings and combinations.

\*Powder coat paint finish.

Dimensions in Inches (mm)