



# Wire Basket Tray System

## Accessories for Wire Basket Tray, Preformed Fittings

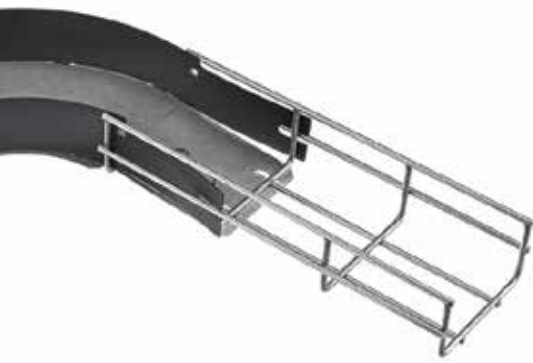

### Features

- Labor and time savings
- Consistent installations
- For round and flat tray
- Steel pre-galvanized bases
- Interlocking polymer side walls
- Splicing hardware included
- Available with steel side walls

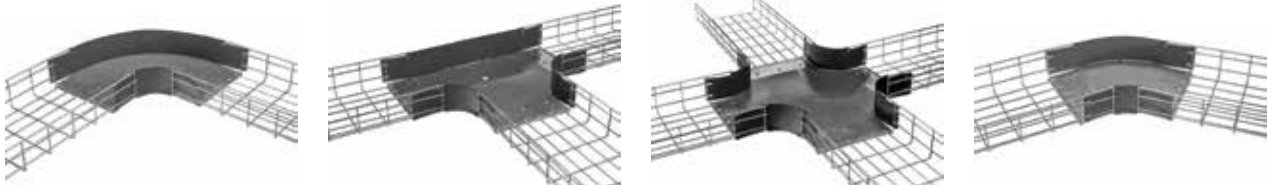

Tray Size	Tray Width	90 Degree	Tee	Intersection	45 Degree	30 Degree
2" (51) Deep	4"(102)	<b>HBTR0204</b>	<b>HBTT0204</b>	<b>HBTI0204</b>	<b>HBT450204</b>	<b>HBT300204</b>
	6"(152)	<b>HBTR0206</b>	<b>HBTT0206</b>	<b>HBTI0206</b>	<b>HBT450206</b>	<b>HBT300206</b>
	8"(203)	<b>HBTR0208</b>	<b>HBTT0208</b>	<b>HBTI0208</b>	<b>HBT450208</b>	<b>HBT300208</b>
	12"(305)	<b>HBTR0212</b>	<b>HBTT0212</b>	<b>HBTI0212</b>	<b>HBT450212</b>	<b>HBT300212</b>
	16"(406)	<b>HBTR0216</b>	<b>HBTT0216</b>	<b>HBTI0216</b>	<b>HBT450216</b>	<b>HBT300216</b>
	18"(457)	<b>HBTR0218</b>	<b>HBTT0218</b>	<b>HBTI0218</b>	<b>HBT450218</b>	<b>HBT300218</b>
	20"(508)	<b>HBTR0220</b>	<b>HBTT0220</b>	<b>HBTI0220</b>	<b>HBT450220</b>	<b>HBT300220</b>
	24"(610)	<b>HBTR0224</b>	<b>HBTT0224</b>	<b>HBTI0224</b>	<b>HBT450224</b>	<b>HBT300224</b>
4" (102) Deep	4"(102)	<b>HBTR0404</b>	<b>HBTT0404</b>	<b>HBTI0404</b>	<b>HBT450404</b>	<b>HBT300404</b>
	6"(152)	<b>HBTR0406</b>	<b>HBTT0406</b>	<b>HBTI0406</b>	<b>HBT450406</b>	<b>HBT300406</b>
	8"(203)	<b>HBTR0408</b>	<b>HBTT0408</b>	<b>HBTI0408</b>	<b>HBT450408</b>	<b>HBT300408</b>
	12"(305)	<b>HBTR0412</b>	<b>HBTT0412</b>	<b>HBTI0412</b>	<b>HBT450412</b>	<b>HBT300412</b>
	16"(406)	<b>HBTR0416</b>	<b>HBTT0416</b>	<b>HBTI0416</b>	<b>HBT450416</b>	<b>HBT300416</b>
	18"(457)	<b>HBTR0418</b>	<b>HBTT0418</b>	<b>HBTI0418</b>	<b>HBT450418</b>	<b>HBT300418</b>
	20"(508)	<b>HBTR0420</b>	<b>HBTT0420</b>	<b>HBTI0420</b>	<b>HBT450420</b>	<b>HBT300420</b>
	24"(610)	<b>HBTR0424</b>	<b>HBTT0424</b>	<b>HBTI0424</b>	<b>HBT450424</b>	<b>HBT300424</b>
6" (152) Deep	8"(203)	<b>HBTR0608</b>	<b>HBTT0608</b>	<b>HBTI0608</b>	<b>HBT450608</b>	<b>HBT300608</b>
	12"(305)	<b>HBTR0612</b>	<b>HBTT0612</b>	<b>HBTI0612</b>	<b>HBT450612</b>	<b>HBT300612</b>
	16"(406)	<b>HBTR0616</b>	<b>HBTT0616</b>	<b>HBTI0616</b>	<b>HBT450616</b>	<b>HBT300616</b>
	18"(457)	<b>HBTR0618</b>	<b>HBTT0618</b>	<b>HBTI0618</b>	<b>HBT450618</b>	<b>HBT300618</b>
	20"(508)	<b>HBTR0620</b>	<b>HBTT0620</b>	<b>HBTI0620</b>	<b>HBT450620</b>	<b>HBT300620</b>
	24"(610)	<b>HBTR0624</b>	<b>HBTT0624</b>	<b>HBTI0624</b>	<b>HBT450624</b>	<b>HBT300624</b>

Note: Add **BK** suffix for black base.  
Add **SW** suffix for steel side walls.

Dimensions in Inches (mm)