



15A, 125V, 2 Pole, 2 Wire Non-Grounding, Valise® Plugs

IP20
SUITABILITY



15A 125V
NEMA 1-15R
UL CSA
0.5 HP



15A 125V
NEMA 1-15P
UL CSA
0.5 HP




HBL5865VY

Description	Cord Diameter	Catalog Number
Yellow nylon, non-polarized.	.218"-.385" (5.5-9.8)	-
Yellow nylon, polarized.	.218"-.385" (5.5-9.8)	-
Black nylon, polarized.	Type 17/2 "SVT" cord	-

Valise® Connector Bodies

Description	Cord Diameter	Catalog Number
Yellow nylon.	.218"-.385" (5.5-9.8)	HBL5869VY

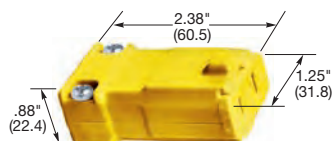

HBL5869VY




15A, 277V AC, 2 Pole, 3 Wire Grounding, Plugs



15A 277V AC
NEMA 7-15R
UL CSA
2 HP



15A 277V AC
NEMA 7-15P
2 HP

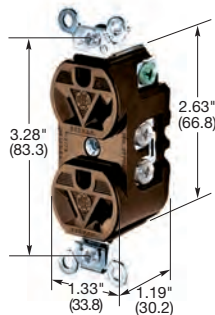


HBL5302

Description	Cord Diameter	Catalog Number
Finger grip, black elastomer.	.312"-.468" (7.9-11.9)	-

Receptacles and Connector Bodies

Description	Cord Diameter	Catalog Number
Receptacle, flush duplex, brown, back and side wired.	-	HBL5302
Connector Body, phenolic and steel body.	.296"-.625" (7.5-15.9)	HBL5324

Note: *Not UL Listed.
Horsepower ratings are AC only.
See pages A-46 and A-47 for accessories.

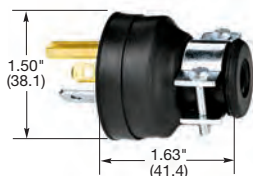

HBL5929



20A, 250V, 2 Pole, 2 Wire Non-Grounding, Valise® Plugs


IP20
SUITABILITY



20A 250V
NEMA 2-20R
UL Listed
2 HP



20A 250V
NEMA 2-20P
UL Listed
2 HP

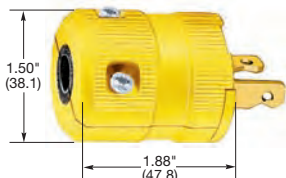


HBL9758VY

Description	Cord Diameter	Catalog Number
Yellow nylon.	.220"-.660" (5.6-16.8)	-

Receptacle, Single

Description	Catalog Number
Black phenolic.	HBL5552B

Note: Horsepower ratings are AC only and apply to plugs and receptacles only.
See pages A-46 and A-47 for accessories.

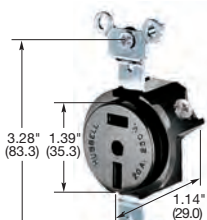

HBL5552B

Dimensions in Inches (mm)

Straight Blade Devices

20 Ampere, 125/250 Volts, 3Ø 250 Volts AC and 3ØY 120/208V AC

3 Pole, 3 Wire Non-Grounding; 3 Pole, 4 Wire Grounding; 4 Pole 4 Wire Non-Grounding



20A, 125/250V, 3 Pole, 3 Wire Non-Grounding, Receptacles and Plugs

IP20
SUITABILITY




20A 125V/250V
NEMA 10-20R
UL Listed
2(1) HP



20A 125V/250V
NEMA 10-20P
UL Listed
2(1) HP

Description	Cord Diameter	Catalog Number
Receptacle, black phenolic.	-	HBL6810
Plug, Insulgrip®, nylon.	.385"-.780" (9.8-19.8)	- HBL9977C

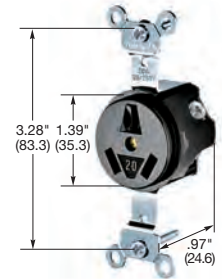

HBL6810

Note: Horsepower ratings listed above are AC only.

Horsepower ratings not in parentheses are phase to phase (208 to 240V AC).

Those in parentheses are phase to neutral (120V AC).

See pages A-46 and A-47 for accessories.



20A, 125/250V, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

IP20
SUITABILITY




20A 125V/250V
NEMA 14-20R
UL CSA
2(1) HP




20A 125V/250V
NEMA 14-20P
UL CSA
2(1) HP

Description	Cord Diameter	Catalog Number
Receptacle, black nylon body, back and side wired.	-	HBL8410
Plug, nylon, angle 4-position.	.390"-.775" (9.9-19.7)	- HBL8411C

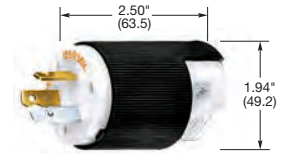

HBL9977C

Note: See pages A-46 and A-47 for accessories.

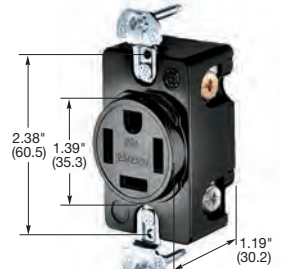

HBL8410



20A, 3Ø 250V AC, 3 Pole, 4 Wire Grounding, Receptacles and Plugs

IP20
SUITABILITY




20A 3Ø 250V AC
NEMA 15-20R
UL CSA
3 HP



20A 3Ø 250V AC
NEMA 15-20P
UL CSA
3 HP

Description	Cord Diameter	Catalog Number
Receptacle, black nylon body, back and side wired.	-	HBL8420
Plug, nylon, angle 4-position.	.390"-.775" (9.9-19.7)	- HBL8421C

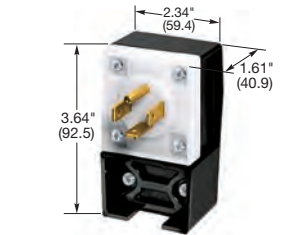


HBL8411C

Note: Horsepower ratings listed above are AC only.

Horsepower ratings not in parentheses are phase to phase (208 to 240V AC).

Horsepower ratings in parentheses are phase to neutral (120V AC).

See pages A-46 and A-47 for accessories.

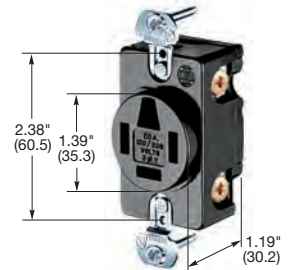

HBL8420



20A, 3ØY 120/208V AC, 4 Pole, 4 Wire Non-Grounding, Receptacles and Plugs

IP20
SUITABILITY




20A 3ØY 120/208V AC
NEMA 18-20R
UL Listed
2 HP



20A 3ØY 120/208V AC
NEMA 18-20P
UL Listed
2 HP

Description	Cord Diameter	Catalog Number
Receptacle, black nylon body.	-	HBL7250
Plug, nylon, angle, 4-position.	.390"-.775" (9.9-19.7)	- HBL7251C

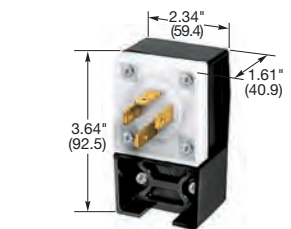

HBL7251C

Note: Horsepower ratings are phase to phase (208 to 240V AC).

Weatherproof boots for plugs not available.

See pages A-46 and A-47 for accessories.

Dimensions in Inches (mm)