



HBL2751




HBL2755

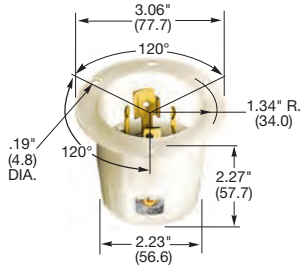

HBL2753

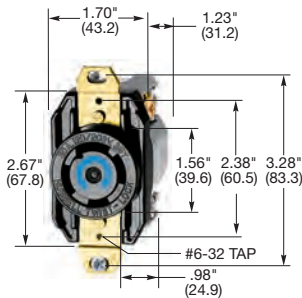

HBL2750

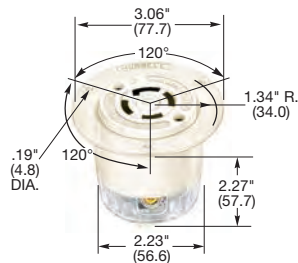

HBL2756

IP20
SUITABILITY



30A 3ØY
120/208V AC
NEMA L18-30P
UL Listed
3 HP



30A 3ØY
277/480V AC
NEMA L19-30P
UL Listed
10 HP



30A 3ØY
347/600V AC
NEMA L20-30P
UL Listed

Plugs

Description	Cord Dia.	Catalog Number		
Black and white nylon.	.350"-1.150" (9-29)	HBL2751	HBL2761	HBL2771

Note: See page B-53 for accessories.

Flanged Inlets

Description	Catalog Number		
Nylon casing, back wired.	HBL2755	HBL2765	HBL2775

Note: See page B-52 for accessories.

IP20
SUITABILITY



30A 3ØY
120/208V AC
NEMA L18-30R
UL Listed
3 HP



30A 3ØY
277/480V AC
NEMA L19-30R
UL Listed
10 HP



30A 3ØY
347/600V AC
NEMA L20-30R
UL Listed

Connector Bodies

Description	Cord Dia.	Catalog Number		
Black and white nylon.	.350"-1.150" (9-29)	HBL2753	HBL2763	HBL2773

Note: See page B-53 for accessories.

Single Flush Receptacles

Description	Catalog Number		
Black nylon face, back and side wired.	HBL2750	HBL2760	HBL2770

Note: See page B-52 for accessories.

Flanged Receptacles

Description	Catalog Number		
Nylon casing, back wired.	HBL2756	HBL2766	HBL2776

Note: See page B-52 for accessories.

See page B-69 for technical information on Twist-Lock devices.