

IP20
 SUITABILITY



30A 480V AC
 NEMA L8-30P
 UL/CSA
 5 HP




30A 600V AC
 NEMA L9-30P
 UL/CSA

Plugs

Description	Cord Dia.	Catalog Number
Black and white nylon.	.325"-.930" (8.25-24)	HBL2641 HBL2651

Note: See page B-51 for accessories.

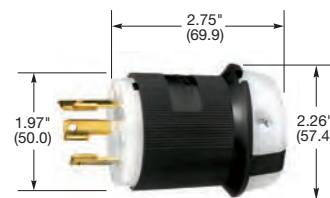


HBL2651

Flanged Inlets

Description	Catalog Number
Nylon casing, back wired.	HBL2645 HBL2655

Note: See page B-50 for accessories.

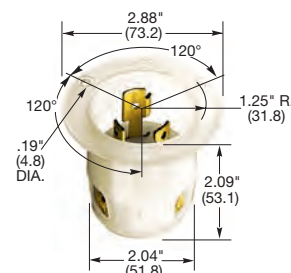

HBL2655

IP20
 SUITABILITY



30A 480V AC
 NEMA L8-30R
 UL/CSA
 5 HP



30A 600V AC
 NEMA L9-30R
 UL/CSA

Connector Bodies

Description	Cord Dia.	Catalog Number
Black and white nylon.	.325"-.930" (8.25-24)	HBL2643 HBL2653

Note: See page B-51 for accessories.




HBL2653

Single Flush Receptacles

Description	Catalog Number
Black nylon face, back and side wired.	HBL2640 HBL2650

Note: See page B-50 for accessories.

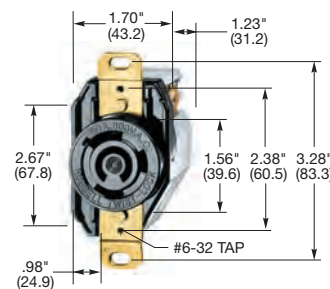


HBL2650

Flanged Receptacles

Description	Catalog Number
Nylon casing, back wired.	HBL2646 HBL2656

Note: See page B-50 for accessories.
 See page B-69 for technical information on Twist-Lock devices.

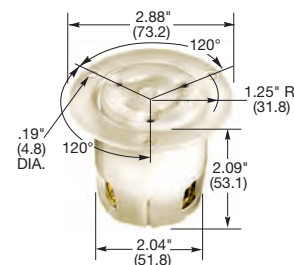

HBL2656

Dimensions in Inches (mm)