



Non-NEMA Twist-Lock® Devices 20 Ampere, 250, 125/250 Volts and 3ØY 120/208 Volts AC Insulgrip® Plugs, Flanged Inlets, Connector Bodies and Receptacles




HBL9965C

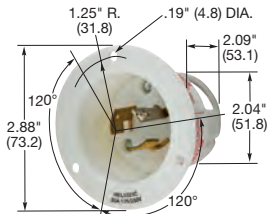

HBL3325C

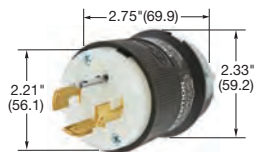


HBL7411C

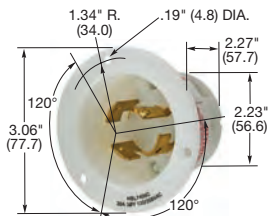

HBL7408C

For Replacement Use Only

 IP20
SUITABILITY



Plugs

Description	Cord Dia.	Catalog Number	
Black and white nylon.	.360"-.930" (9-24)	HBL9965GCB	HBL9965C
Corrosion resistant, yellow nylon.	.360"-.930" (9-24)	-	HBL99CM65C

Note: See page B-51 for accessories.


Flanged Inlets

Description	Catalog Number
Nylon casing, back wired.	- HBL3325C

Note: See page B-50 for accessories.

For Replacement Use Only

 IP20
SUITABILITY



Plugs

Description	Cord Dia.	Catalog Number	
Black and white nylon.	.350"-1.150" (9-29)	HBL7411GCB	HBL7411C

Note: See page B-53 for accessories.

Flanged Inlets

Description	Catalog Number
Nylon casing, back wired.	- HBL7408C

Note: See page B-52 for accessories.

See page B-69 for technical information.
The devices shown on this page are not listed by Underwriters Laboratories Inc.
and are for replacement use only in existing installations.

Dimensions in Inches (mm)

CAUTION: To avoid electrical shock, review premises carefully and do not use if slot or blade configuration (design) is already in a circuit having a rating differing from the rating of this device.