



Non-NEMA Twist-Lock® Devices 30 Ampere, 250, 125/250 Volts and 3ØY 120/208 Volts AC

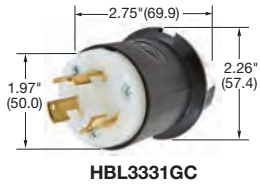

HBL3331GC

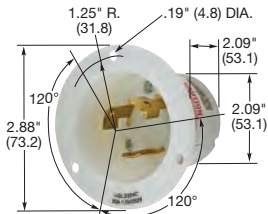

HBL3334C



HBL3431C

For Replacement Use Only

IP20
SUITABILITY



30A 250V
Non-NEMA
Not UL listed



30A 125/250V
Non-NEMA
Not UL Listed

Insulgrip® Plugs

Description	Cord Dia.	Catalog Number	
Black and white nylon.	.360"-.930" (9-24)	HBL3331GC	HBL3331C

Note: See page B-51 for accessories.


Insulgrip® Flanged Inlets

Description	Catalog Number
Nylon casing, back wired.	HBL3334C


Note: See page B-50 for accessories.

For Replacement Use Only

 IP20
SUITABILITY



30A 3Ø 250V AC
Non-NEMA
Not UL Listed

 

Non-NEMA
30A 3Ø Y
120/208V AC
Not UL Listed

Insulgrip® Plugs

Description	Cord Dia.	Catalog Number	
Black and white nylon.	.350"-1.150" (9-29)	HBL3431GCB	HBL3431C

Note: See page B-53 for accessories.

See page B-69 for technical information.

The devices shown on this page are not listed by Underwriters Laboratories Inc.
and are for replacement use only in existing installations.