

# Straight Blade Devices

## Residential Grade Duplex and Decorator Receptacles

### 15A 125V Duplex and Decorator Weather Resistant and Tamper-Resistant Receptacles



### Product Dimensions Inches (mm)

	Duplex	Decorator	Single	Single Decorator
A	4.19" (106.4)	4.19" (106.4)	4.20" (106.7)	4.20" (106.7)
B	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)
C	1.41" (35.8)	—	1.41" (35.8)	—
D	0.93" (23.6)	0.93" (23.6)	1.01" (25.7)	1.01" (25.7)
E	2.62" (66.6)	2.62" (66.6)	2.08" (52.8)	2.08" (52.8)




RR15SWWRTR

RRD15SWTR

Wiring		Push and Side Wired	
Grounding		Self-Grounding	
Rating	Color	Duplex	Decorator
NEMA 5-15,	Black	<b>RR15SBKWRTR</b>	<b>RRD15SBKWRTR</b>
15A 125V	Brown	<b>RR15SWRTR</b>	<b>RRD15SWRTR</b>
	Gray	<b>RR15SGYWRTR</b>	<b>RRD15SGYWRTR</b>
	Ivory	<b>RR15IWRTR</b>	<b>RRD15IWRTR</b>
	Light Almond	<b>RR15SLAWRTR</b>	<b>RRD15SLAWRTR</b>
	White	<b>RR15SWRTR</b>	<b>RRD15SWRTR</b>

Note: See page R-6 for tamper-resistant and weather resistant descriptions.

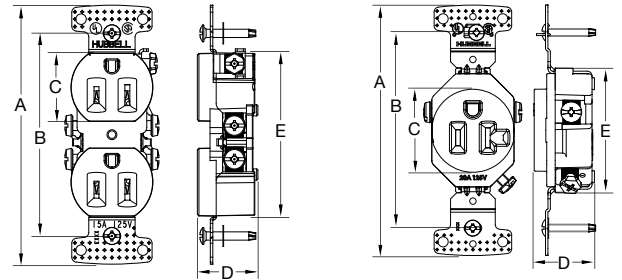

## Residential Grade Single and Single Decorator Receptacles

### 15A and 20A 125V and 250V Single Self-Grounding Receptacles



Style	Color	Standard		Tamper-Resistant		Weather Resistant	Weather Resistant Tamper-Resistant
		Duplex	Decorator	Duplex	Decorator	Duplex	Duplex
NEMA 5-15, 15A 125V 	Almond	—	—	<b>RR151ALTR</b>	<b>RRD151ALTR</b>	—	<b>RR151ALWRTR</b>
	Black	<b>RR151BK</b>	<b>RRD151BK</b>	<b>RR151BKTR</b>	<b>RRD151BKTR</b>	—	<b>RR151BKWRTR</b>
	Brown	<b>RR151</b>	<b>RRD151</b>	<b>RR151TR</b>	<b>RRD151TR</b>	—	<b>RR151WRTR</b>
	Gray	<b>RR151GY</b>	<b>RRD151GY</b>	<b>RR151GYTR</b>	<b>RRD151GYTR</b>	—	<b>RR151GYWRTR</b>
	Ivory	<b>RR151I</b>	<b>RRD151I</b>	<b>RR151ITR</b>	<b>RRD151ITR</b>	—	<b>RR151IWRTR</b>
	Light Almond	<b>RR151LA</b>	<b>RRD151LA</b>	<b>RR151LATR</b>	<b>RRD151LATR</b>	—	<b>RR151LAWRTR</b>
	White	<b>RR151W</b>	<b>RRD151W</b>	<b>RR151WTR</b>	<b>RRD151WTR</b>	—	<b>RR151WWRTR</b>
NEMA 5-20, 20A 125V 	Almond	—	—	<b>RR201ALTR</b>	<b>RRD201ALTR</b>	—	<b>RR201ALWRTR</b>
	Black	<b>RR201BK</b>	<b>RRD201BK</b>	<b>RR201BKTR</b>	<b>RRD201BKTR</b>	—	<b>RR201BKWRTR</b>
	Brown	<b>RR201</b>	<b>RRD201</b>	<b>RR201TR</b>	<b>RRD201TR</b>	—	<b>RR201WRTR</b>
	Gray	<b>RR201GY</b>	<b>RRD201GY</b>	<b>RR201GYTR</b>	<b>RRD201GYTR</b>	—	<b>RR201GYWRTR</b>
	Ivory	<b>RR201I</b>	<b>RRD201I</b>	<b>RR201ITR</b>	<b>RRD201ITR</b>	—	<b>RR201IWRTR</b>
	Light Almond	<b>RR201LA</b>	<b>RRD201LA</b>	<b>RR201LATR</b>	<b>RRD201LATR</b>	—	<b>RR201LAWRTR</b>
	White	<b>RR201W</b>	<b>RRD201W</b>	<b>RR201WTR</b>	<b>RRD201WTR</b>	—	<b>RR201WWRTR</b>
NEMA 6-15, 15A 250V 	Almond	—	—	—	—	<b>RR155ALWR</b>	—
	Black	<b>RR155BK</b>	<b>RRD155BK</b>	—	—	<b>RR155BKWR</b>	—
	Brown	<b>RR155</b>	<b>RRD155</b>	—	—	<b>RR155WR</b>	—
	Gray	<b>RR155GY</b>	<b>RRD155GY</b>	—	—	<b>RR155GYWR</b>	—
	Ivory	<b>RR155I</b>	<b>RRD155I</b>	—	—	<b>RR155IWR</b>	—
	Light Almond	<b>RR155LA</b>	<b>RRD155LA</b>	—	—	<b>RR155LAWR</b>	—
White	<b>RR155W</b>	<b>RRD155W</b>	—	—	<b>RR155WWR</b>	—	
NEMA 6-20, 20A 250V 	Almond	—	—	—	—	<b>RR205ALWR</b>	—
	Black	<b>RR205BK</b>	<b>RRD205BK</b>	—	—	<b>RR205BKWR</b>	—
	Brown	<b>RR205</b>	<b>RRD205</b>	—	—	<b>RR205WR</b>	—
	Gray	<b>RR205GY</b>	<b>RRD205GY</b>	—	—	<b>RR205GYWR</b>	—
	Ivory	<b>RR205I</b>	<b>RRD205I</b>	—	—	<b>RR205IWR</b>	—
	Light Almond	<b>RR205LA</b>	<b>RRD205LA</b>	—	—	<b>RR205LAWR</b>	—
White	<b>RR205W</b>	<b>RRD205W</b>	—	—	<b>RR205WWR</b>	—	