

Straight Blade Devices



Special Use Products

Floor Box Assemblies and Display Receptacles



5236BOX



3799G

Floor Box Assemblies		Brushed Brass Plate
Rating	Description	
NEMA 5-15, 15A 125V 	Specification grade single receptacle, gasketing and floor rated single gang steel box	5236BOX

Display Receptacles		
Description	Smooth Brushed Brass Finish	Nickel Plated Finish
Specification grade single receptacle	3799G	3799GS

Nightlight Only



3799G

Nightlight Devices		Catalog Number
Description		
LED 1.5 Lumen nightlight with polycarbonate full face lens for maximum illumination, 6 in. pre-wired stranded wire		D100NLIV D100NLLA D100NLW

Clock Hangers



2828GS



RR151CHSSTR



RR151CHWTR



RR1510W

Rating	Specification Grade		
	Description	Smooth Brushed Brass Plate	Nickel Plated Finish
NEMA 5-15, 15A 125V 	Specification grade single receptacle	2828G	2828GS
NEMA 5-20, 20A 125V 		—	—


Residential Grade		Single Receptacle	Duplex
Description	Material/Color	Tamper-Resistant	Tamper-Resistant
Clock hanger/recessed receptacle, grounding, side wire terminations	Brass Stainless Steel	RR151CHBSTR RR151CHSSTR	— —
	Ivory Light Almond White	RR151CHITR — RR151CHWTR	RR1510I RR1510LA RR1510W
	Brass Stainless Steel	— RR201CHSSTR	— —
	Ivory White	RR201CHITR RR201CHWTR	— —

Note: See Section O for floor and under cabinet box options.


Note: See page R-6 for tamper-resistant description.

Product Dimensions Inches (mm)


	Display Receptacles	Residential Clock Hanger	Nightlight Only
A	4.50" (114.3)	4.63" (117.5)	4.20" (106.8)
B	2.38" (60.5)	2.51" (63.8)	3.28" (83.4)
C	2.75" (69.9)	2.88" (73.0)	1.74" (44.2)
D	1.86" (47.2)	2.10" (53.3)	1.13" (33.3)
E	3.28" (83.3)	2.08" (52.8)	2.73" (69.4)
F	—	1.51" (38.4)	1.16" (29.3)

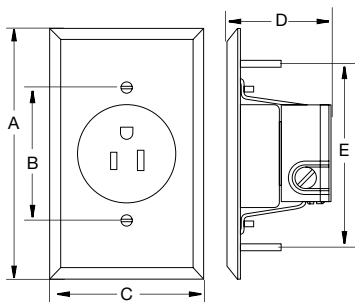

Display Receptacles

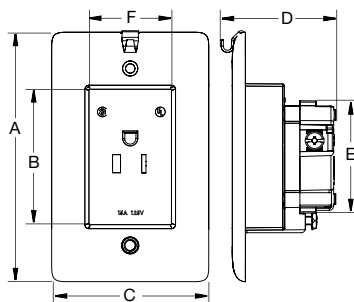

Residential Clock Hanger

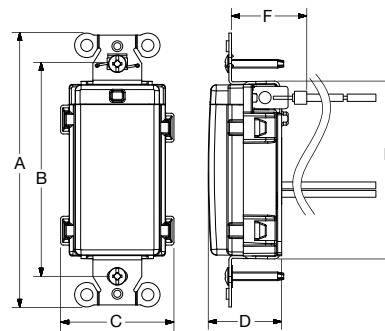

Nightlight Only