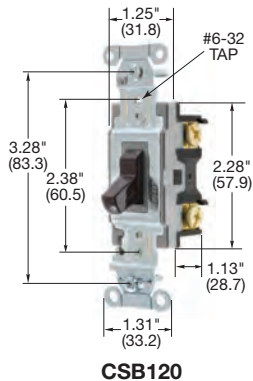


**Specification Grade Commercial Series,
15A, 120-277V AC**


| Description | Toggle Color | Single Pole | Double Pole | Three Way | Four Way |
|------------------------------------|--------------|-----------------|-----------------|-----------------|-----------------|
| Toggle, back and side wired. | Almond | CSB115AL | CSB215AL | CSB315AL | CSB415AL |
| | Black | CSB115BK | CSB215BK | CSB315BK | CSB415BK |
| | Brown | CSB115 | CSB215 | CSB315 | CSB415 |
| | Gray | CSB115GY | CSB215GY | CSB315GY | CSB415GY |
| | Ivory | CSB115I | CSB215I | CSB315I | CSB415I |
| | Light Almond | CSB115LA | CSB215LA | CSB315LA | CSB415LA |
| | White | CSB115W | CSB215W | CSB315W | CSB415W |


**Specification Grade Commercial Series,
20A, 120-277V AC**

| Description | Toggle Color | Single Pole | Double Pole | Three Way | Four Way |
|------------------------------------|--------------|-----------------|-----------------|-----------------|-----------------|
| Toggle, back and side wired. | Almond | CSB120AL | CSB220AL | CSB320AL | CSB420AL |
| | Black | CSB120BK | CSB220BK | CSB320BK | CSB420BK |
| | Brown | CSB120 | CSB220 | CSB320 | CSB420 |
| | Gray | CSB120GY | CSB220GY | CSB320GY | CSB420GY |
| | Ivory | CSB120I | CSB220I | CSB320I | CSB420I |
| | Light Almond | CSB120LA | CSB220LA | CSB320LA | CSB420LA |
| | Red | CSB120R | CSB220R | CSB320R | CSB420R |
| | White | CSB120W | CSB220W | CSB320W | CSB420W |

**Specification Grade Commercial Series,
15A, 120-277V AC**

| Description | Toggle Color | Single Pole | Double Pole | Three Way | Four Way |
|-----------------------------|--------------|----------------|-------------|----------------|----------|
| Toggle, side wired only. | Almond | CS115AL | — | CS315AL | — |
| | Black | CS115BK | — | CS315BK | — |
| | Brown | CS115 | — | CS315 | — |
| | Gray | CS115GY | — | CS315GY | — |
| | Ivory | CS115I | — | CS315I | — |
| | Light Almond | CS115LA | — | CS315LA | — |
| | White | CS115W | — | CS315W | — |

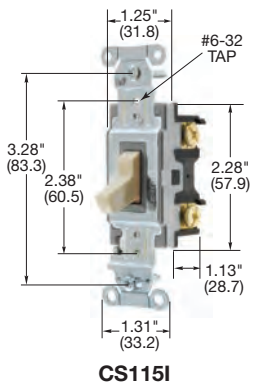
**Specification Grade Commercial Series,
20A, 120-277V AC**

| Description | Toggle Color | Single Pole | Double Pole | Three Way | Four Way |
|-----------------------------|--------------|----------------|-------------|----------------|----------|
| Toggle, side wired only. | Almond | CS120AL | — | CS320AL | — |
| | Black | CS120BK | — | CS320BK | — |
| | Brown | CS120 | — | CS320 | — |
| | Gray | CS120GY | — | CS320GY | — |
| | Ivory | CS120I | — | CS320I | — |
| | Light Almond | CS120LA | — | CS320LA | — |
| | White | CS120W | — | CS320W | — |

Note: See page D-9 for pre-wired/leaded devices.
See page D-13 for accessories.
See page D-15 for wallplates.
See page D-20 for technical information.

HP Conversion Chart

| | 120V | 208V | 240V | 277V AC |
|-----|------|-------|------|---------|
| 15A | .5HP | 1.5HP | 2HP | 2HP |
| 20A | 1HP | 2HP | 2HP | 2HP |

Dimensions in Inches (mm)