




SNAP8362GYS

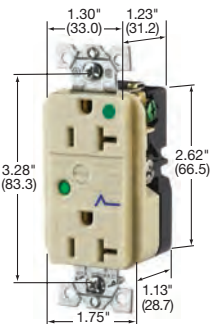

HBL8362ISA

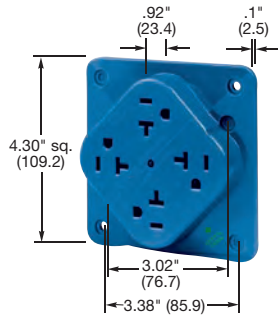

HBL420HS

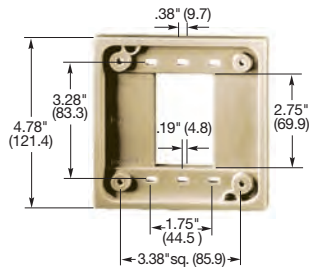

HBL4API



HBL6PSHG

Dimensions in Inches (mm)

Hospital Grade ● Circuit Guard® Receptacles



SNAPConnect® Tamper-Resistant, surge suppression receptacle, smooth face, duplex. Requires connector on page L-15, sold separately.

Surge suppression receptacles with light and alarm, 240 joules/15000A per mode.

Isolated ground, surge suppression receptacles with light and alarm, 240 joules/15000A per mode.

4-PLEX® surge suppression receptacles with lights, 80 joules/6500A per mode.



15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

Description	Color	Catalog Number	
SNAPConnect® Tamper-Resistant, surge suppression receptacle, smooth face, duplex. Requires connector on page L-15, sold separately.	Blue	SNAP8262S	SNAP8362S
	Gray	SNAP8262GYS	SNAP8362GYS
	Ivory	SNAP8262IS	SNAP8362IS
	Light Almond	SNAP8262LAS	SNAP8362LAS
	Red	SNAP8262RS	SNAP8362RS
	White	SNAP8262WS	SNAP8362WS
Surge suppression receptacles with light and alarm, 240 joules/15000A per mode.	Almond	HBL8262ALSA	HBL8362ALSA
	Blue	HBL8262SA	HBL8362SA
	Gray	HBL8262GYSA	HBL8362GYSA
	Ivory	HBL8262ISA	HBL8362ISA
	Red	HBL8262RSA	HBL8362RSA
	White	HBL8262WSA	HBL8362WSA
Isolated ground, surge suppression receptacles with light and alarm, 240 joules/15000A per mode.	Blue	IG8262SA	IG8362SA
	Gray	IG8262GYSA	IG8362GYSA
	Ivory	IG8262ISA	IG8362ISA
	Orange	IG8262OSA	IG8362OSA
	Red	IG8262RSA	IG8362RSA
	White	IG8262WSA	IG8362WSA
4-PLEX® surge suppression receptacles with lights, 80 joules/6500A per mode.	Blue	-	HBL420HS
	Ivory	-	HBL420HIS
	Red	-	HBL420HRS

Note: See page Tech-10 for Tamper-Resistant description.

4-PLEX® Accessories

Description	Color	Catalog Number
4-PLEX Adapter Plates for 1- and 2-gang, and 4 in. (101.6) square device boxes.	Blue	HBL4APBL
	Ivory	HBL4API
	Red	HBL4APR
4-PLEX Portable Box. Portable 4 in. (101.6) square box with cord grip. Accepts up to .66 in. (16.8) diameter cord.	Ivory	HBL4PBI

Note: 4-PLEX Box is not UL Listed.

Metallic Power Strip Surge Protected



Description	Catalog Number
15A 125V power strip with filtering, surge protection, 3 hospital grade duplex receptacles, 6 foot power supply cord and hospital grade plug.	HBL6PSHG

Note: See section M for additional information on surge protection products.

Wallplates (Sold Separately)

Configuration	High-Impact Nylon			Plated Steel		Stainless Steel (S/S) Brass	
	Color	Standard	Mid-Size	Chrome Brass Plated	SCH26 SBP26	Smooth S/S	SS26 SSJ26 [▲] SB26
1-Gang	Almond	NP26AL	NPJ26AL				
	Blue	-	NPJ26CBL*				
	Blue	-	NPJ26BL				
	Gray	NP26GY	NPJ26GY				
	Ivory	-	NPJ26C*				
	Ivory	NP26I	NPJ26I				
	Off. White	NP26OW	NPJ26OW				
	Orange	NP26OIG**	-				
	Red	NP26R	NPJ26R				
	White	NP26W	NPJ26W				

Note: *Premarked "COMPUTER ONLY." Lettering is block 1/4" high.
 **Premarked "ISOLATED GROUND." Lettering is block 1/4" high.
 ▲ Jumbo size plate.
 See page A-60 for technical information on 4-PLEX devices.