

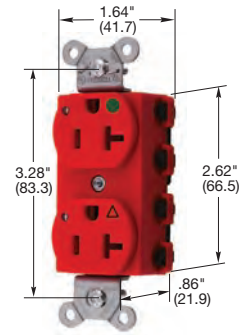
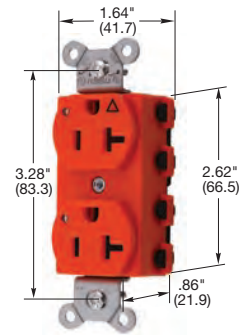


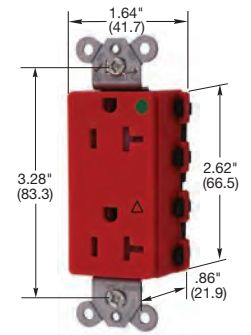

SNAPConnect® Tamper-Resistant Surge Protection Receptacle with Power Indicating LED

Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, surge suppression receptacle, smooth face, duplex.	Blue	SNAP8262S	SNAP8362S
	Gray	SNAP8262GYS	SNAP8362GYS
	Ivory	SNAP8262IS	SNAP8362IS
	Light Almond	SNAP8262LAS	SNAP8362LAS
	Red	SNAP8262RS	SNAP8362RS
	White	SNAP8262WS	SNAP8362WS
Commercial Grade SNAPConnect® Tamper-Resistant, surge suppression receptacle, smooth face, duplex.	Blue	SNAP5262S	SNAP5362S
	Gray	SNAP5262GYS	SNAP5362GYS
	Ivory	SNAP5262IS	SNAP5362IS
	Light Almond	SNAP5262LAS	SNAP5362LAS
	White	SNAP5262WS	SNAP5362WS

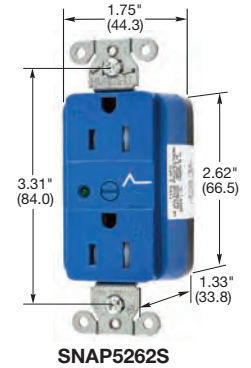

SNAPConnect® Tamper-Resistant Isolated Ground Receptacle

Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP8200IGTR	SNAP8300IGTR
	Red	SNAP8200RIGTR	SNAP8300RIGTR
Hospital Grade ● Style Line® decorator SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP2172IGTR	SNAP2182IGTR
	Red	SNAP2172RIGTR	SNAP2182RIGTR
Commercial Grade, isolated ground	Orange	SNAP5262IGTR	SNAP5362IGTR
Style Line® Decorator	Orange	SNAP2152IGTR	SNAP2162IGTR




SNAPConnect® Isolated Ground Receptacle with Power Indicating LED

Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP8200IGL	SNAP8300IGL
	Red	SNAP8200RIGL	SNAP8300RIGL
Hospital Grade ● Style Line® decorator SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP2172IGL	SNAP2182IGL
	Red	SNAP2172RIGL	SNAP2182RIGL
Commercial Grade, isolated ground	Orange	SNAP5262IGL	SNAP5362IGL
Style Line® Decorator	Orange	SNAP2152IGL	SNAP2162IGL



SNAPConnect® Tamper-Resistant Isolated Ground Receptacle with Power Indicating LED

Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP8200IGLTR	SNAP8300IGLTR
	Red	SNAP8200RIGLTR	SNAP8300RIGLTR
Commercial Grade Style Line® decorator	Orange	SNAP2172IGLTR	SNAP2182IGLTR
	Red	SNAP2172RIGLTR	SNAP2182RIGLTR
Commercial Grade, isolated ground	Orange	SNAP5262IGLTR	SNAP5362IGLTR
Style Line® decorator	Orange	SNAP2152IGLTR	SNAP2162IGLTR

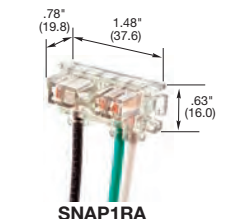

SNAPConnect® Right Angle Pigtailed Connector for General Use

Description	Solid Wire	Stranded Wire
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2, 600V, Polycarbonate housing material	SNAP1RA	SNAP2RA

Note: See page Tech-10 for Power Indicating and Tamper-Resistant descriptions.
 See page M-19 for SNAPConnect® technical information.

Dimensions in Inches (mm)