


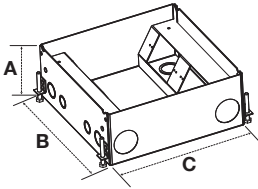



**Dimensions Inches (mm)**

Style	Stamped Steel			Cast Iron
	4-Gang Deep	4-Gang Shallow	8-Gang Deep	4-Gang Shallow
	 <b>HBLCFB301BASE</b>	 <b>HBLCFB401BASE</b>	 <b>HBLCFB501BASE</b>	 <b>HBLCFB401CB</b>
Min. Depth of Pour	4.25" (107.6)	3.00" (76.2)	5.25" (133.4)	3.25" (82.6)
Adjustability	Before pour	Before pour	Before pour	Before pour
Cubic Inch (cm3) Capacity Per Chamber	29.5 cu. in. (483.4 cm3)	25.5 cu. in. (417.9 cm3)	49.5 cu. in. (811.2 cm3)	25.5 cu. in. (417.9 cm3)
Dimensions – A	4.0" (101.6)	2.63" (66.8)	5.13" (130.3)	3.13" (79.5)
Dimensions – B	10.0" (254.0)	10.0" (254.0)	10.0" (254.0)	10.0" (254.0)
Dimensions – C	10.0" (254.0)	10.0" (254.0)	10.0" (254.0)	10.0" (254.0)
Threaded Access Holes – Per Chamber	–	–	–	(2) 1"
Knockouts – Per Chamber	(1) Concentric ½", ¾" (1) Concentric ¾", 1" (1) 1¼"	(3) Concentric ½", ¾"	(1) Concentric ½", ¾" (1) Concentric ¾", 1" (1) 1¼"	–
Concrete Cover Included	✓	✓	✓	✓
Closure Plugs Included	–	–	–	✓

Note: UL File Number E197203.  
CSA File Number LR702145.

**Floor Box Covers with Carpet Recess**

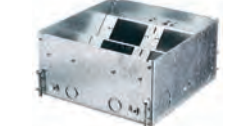Die Cast Metal Cover and Flange Assembly  
Dimensions 10.69" x 10.69"

**HBLTCGNTSW**



Granite

**HBLTCGNTBKS**




Black

**Accessories**

**On-grade Barrier**


The on-grade barrier is intended for use on installations at grade level. This accessory is installed prior to the concrete pour and provides a barrier between the soil. The on-grade barrier comes with leveling feet and anchor points.

**CFBOGPAN4**

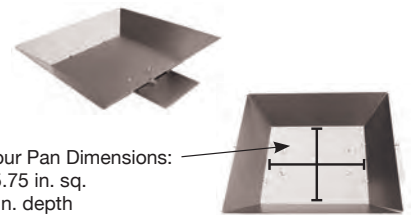

Pour Pan Dimensions:  
15.75 in. sq.  
4 in. depth

**Hubbell – Screw Type Face Plates\***

 

Typical

**HBLST302SGY**



Duplex

**HBLDE301SGY**



Style Line®  
Decorator

**HBLT0310SGY**



Toggle

**HBLTL318SGY**



Single Receptacle  
(1.56" Boss Dia.)

**HBLTL319SGY**



Single Receptacle  
(1.39" Boss Dia.)

**HBLBL300SGY**



Blank

**HBLIMFSGY**



3-Unit Hubbell iSTATION  
(See Network Wiring section  
for module options)

**HBL317SGY**



Hubbell  
6-Port

**Open Systems – Screw Type Face Plates\***

**HBLAM303SGY**



AMP-ACO

**HBLAMP313SGY**



AMP 6-Port

**HBLKR314SGY**



Krone®/Leviton®

**HBLT309SGY**



SYSTIMAX®

**HBLPA308SGY**



Panduit  
Mini-Com®

**HBLN0309SGY**



NORDX® 6-Port  
(Cat. 5e jacks only)

**HBLSI305SGY**



Siemon  
CT® Series

**HBLSI315SGY**



Siemon  
MAX® Series

**HBLOR306SGY**



Ortronics  
Series II®

**HBLORT322SGY**



Ortronics  
TracJack®

Note: \*Catalog numbers indicated are gray, replace "GY" with the following to designate color: "BK" for Black, "I" for Ivory and "WA" for White.

AMP is a registered trademark of Tyco Electronics Corp. Krone® is a registered trademark of Krone, Inc. Leviton® is a registered trademark of Leviton. SYSTIMAX® is a registered trademark of CommScope, Inc. Mini-Com® and Panduit® are registered trademarks of Panduit Corp. NORDX® is a registered trademark of Belden/CDT, Inc. MAX® and CT® Series are registered trademarks of The Siemon Company. TracJack®, Series II® and Ortronics® are registered trademarks of Ortronics/Legrand.