
 

 



 

 

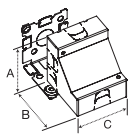

 

 

 

 

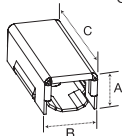

 


End Fittings	Description	Color	HBL500 and HBL750 Series	Description	Color	HBL500 and HBL750 Series		
	Entrance Connector One ¼ in. KO for panel or conduit connection. One ¼ in. chase nipple and locknut furnished.	Ivory White	HBL5786AIV HBL5786AW	A: 1.50" (38.10) B: 1.84" (46.74) C: 3.89" (98.87)	Adjustable Offset Connector Two ½ in. KOs for panel or conduit connection. Eliminates offsetting raceway when connecting to surface type panel boxes. One ½ in. chase nipple and locknut furnished.	Ivory White	HBL5786IV HBL5786W	A: 1.50" (38.10) B: 1.84" (46.74) C: 3.89" (98.87)
	 				 			
	Elbow Box Connector For connecting raceway at right angles to conduit boxes, panel boxes, etc. having ½ in. nipple for trade size conduit.	Ivory	HBL5783IV	A: 2.13" (54.05) B: 1.24" (31.50)	Elbow Conduit Connector For connecting raceway at right angles to ½ in. trade size conduit or armored cable connectors	Ivory	HBL5784IV	A: 2.13" (54.05) B: 1.24" (31.50)
 				 				
Combination Connector For connecting raceway without offsetting to any 3.25 in. (83.00) or 4 in. (102.00) outlet box mounted on the surface with a KO for ½ in. trade size conduit. Spring steel bushing eliminates need for conduit nipple and locknut.	Ivory White	HBL5785IV HBL5785W	A: 1.50" (38.10) B: 1.84" (46.74) C: 3.89" (98.87)	Corner Box For connecting HBL500 or HBL750 Raceway from ceiling or corner. Each leg of base has ½ in. trade size KO.	Ivory White	HBL5719IV HBL5719W	A: 2.50" (63.50) B: 2.50" (63.50) C: 2.40" (60.96)	
 				 				

Fittings	Description	Color	HBL500 Series	HBL750 Series	Description	Color	HBL500 and HBL750 Series			
	Mounting Strap (one- or two-hole) For mounting HBL500 or HBL750 Raceway to surface. Convert to one-hole by breaking off at score.	Ivory White	HBL504IV HBL504W	A: .58" (14.73) B: .50" (12.70)	HBL704IV HBL704W	A: .90" (22.86) B: .50" (12.70)	Support Clip For supporting lengths of HBL500 or HBL750 Raceway.	Ivory White	HBL5703IV HBL5703W	A: 2.51" (63.75)
	 				 					
	Connection Cover To cover potential openings where two lengths of HBL500 or HBL750 Raceway come together.	Ivory White	HBL506IV HBL506W	A: .60" (15.24) B: .80" (20.31)	HBL706IV HBL706W	A: .91" (23.10) B: .80" (20.31)	Flexible Section For getting around offsets, side bends, twisted turns or curved surfaces.	Ivory	HBL5700FIV	A: 18.00" (457.20)
	 				 					
Transition Fitting For transitioning from either Wiremold® V500 to Hubbell HBL500 Raceway or Wiremold® V700 to Hubbell HBL750 Raceway.	Ivory	HBL500TFIV	A: .65" (16.51) B: .89" (22.61) C: 2.15" (54.61)	HBL750TFIV	A: .98" (24.89) B: .89" (22.61) C: 2.15" (54.61)					
 										
Bushing Protect wires from potential abrasion. Fits into end of HBL500 or HBL750 Raceway.	Steel*	HBL502B	A: .35" (8.83) B: .70" (17.68)	HBL702B	A: .60" (15.24) B: .70" (17.68)					
 										

Note: *Zinc Plated Steel.

Wiremold® is a registered trademark of the Wiremold Company.

Dimensions in Inches (mm)