

Features

- Smooth, quiet rocker
- Self-grounding feature is standard
- Ultrasonically welded cover and base
- Operating temperature: -20°C to 60°C
- UL Listed E3896, CSA Certified

Single Pole Decorator Quiet Rocker Switches

Description	Single Pole	Single Pole, Illuminated	Single Pole, Pilot Light	Single Pole with ON/OFF Marking
Termination	Self-Grounding, Push, Back and Side Wire	Self-Grounding, Push, Back and Side Wire	Self-Grounding, Push, Back and Side Wire	Self-Grounding, Push, Back and Side Wire
Rating	15A 120-277V AC	15A 120V AC	15A 120V AC	15A 120-277V AC
Black	RSD115BK	—	—	—
Brown	RSD115	—	—	—
Gray	RSD115GY	—	—	—
Ivory	RSD115I	RSD115ILI*	RSD115PLI**	RSD115IM
Light Almond	RSD115LA	RSD115ILLA*	RSD115PLLA**	RSD115LAM
White	RSD115W	RSD115ILW*	RSD115PLW**	RSD115WM

Note: *Light glows through the top portion of the rocker when switch is in the off position. Does not require a neutral wire.
 **Light glows through the top portion of the rocker when switch is in the on position. Requires a neutral wire.



RSD115W



RSD115PLW



RSD115WM

Double Pole, Three Way and Four Way Decorator Quiet Rocker Switches


Description	Double Pole	Three Way	Three Way, Illuminated	Four Way
Termination	Self-Grounding, Back and Side Wire	Self-Grounding, Push, Back and Side Wire	Self-Grounding, Push, Back and Side Wire	Self-Grounding, Back and Side Wire
Rating	15A 120-277V AC	15A 120-277V AC	15A 120V AC	15A 120-277V AC
Black	RSD215BK	RSD315BK	—	—
Brown	RSD215	RSD315	—	RSD415
Gray	RSD215GY	RSD315GY	—	RSD415GY
Ivory	RSD215I	RSD315I	RSD315ILI*	RSD415I
Light Almond	RSD215LA	RSD315LA	RSD315ILLA*	RSD415LA
White	RSD215W	RSD315W	RSD315ILW*	RSD415W

Note: *Light glows through the top portion of the rocker when switch is in the off position. Does not require a neutral wire.



RSD215W

Dimensions

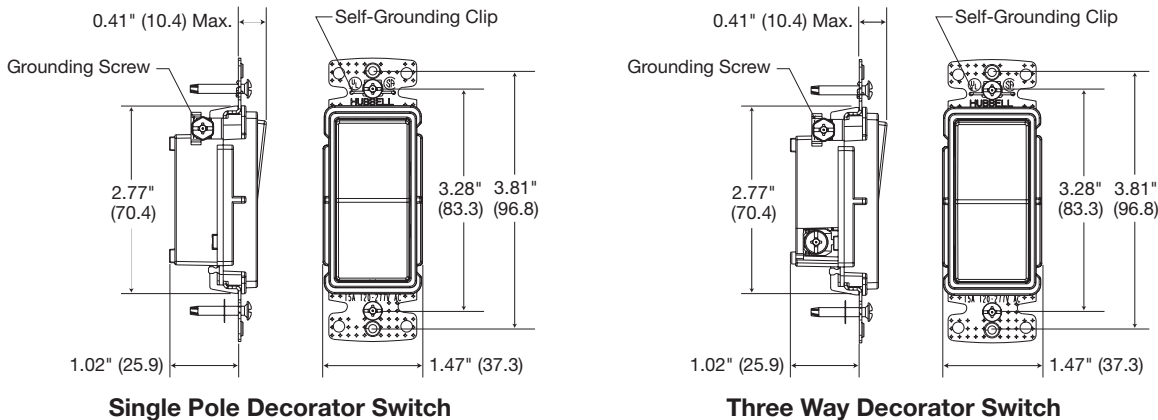

Dimensions in Inches (mm)