


Quick and Easy Does It



Residential exclusive “Quick Thread” makes installation of wallplates and receptacles quicker and easier. Just push in the screw and turn. Provides branch circuit convenience power in duplex and single configurations.

- Smooth indented face appearance
- Terminal screws accepts up to #12 AWG
- Push wire designed for #14 AWG solid copper wire only
- Operating temperature: -20°C to 60°C
- UL Listed E2186, CSA Certified

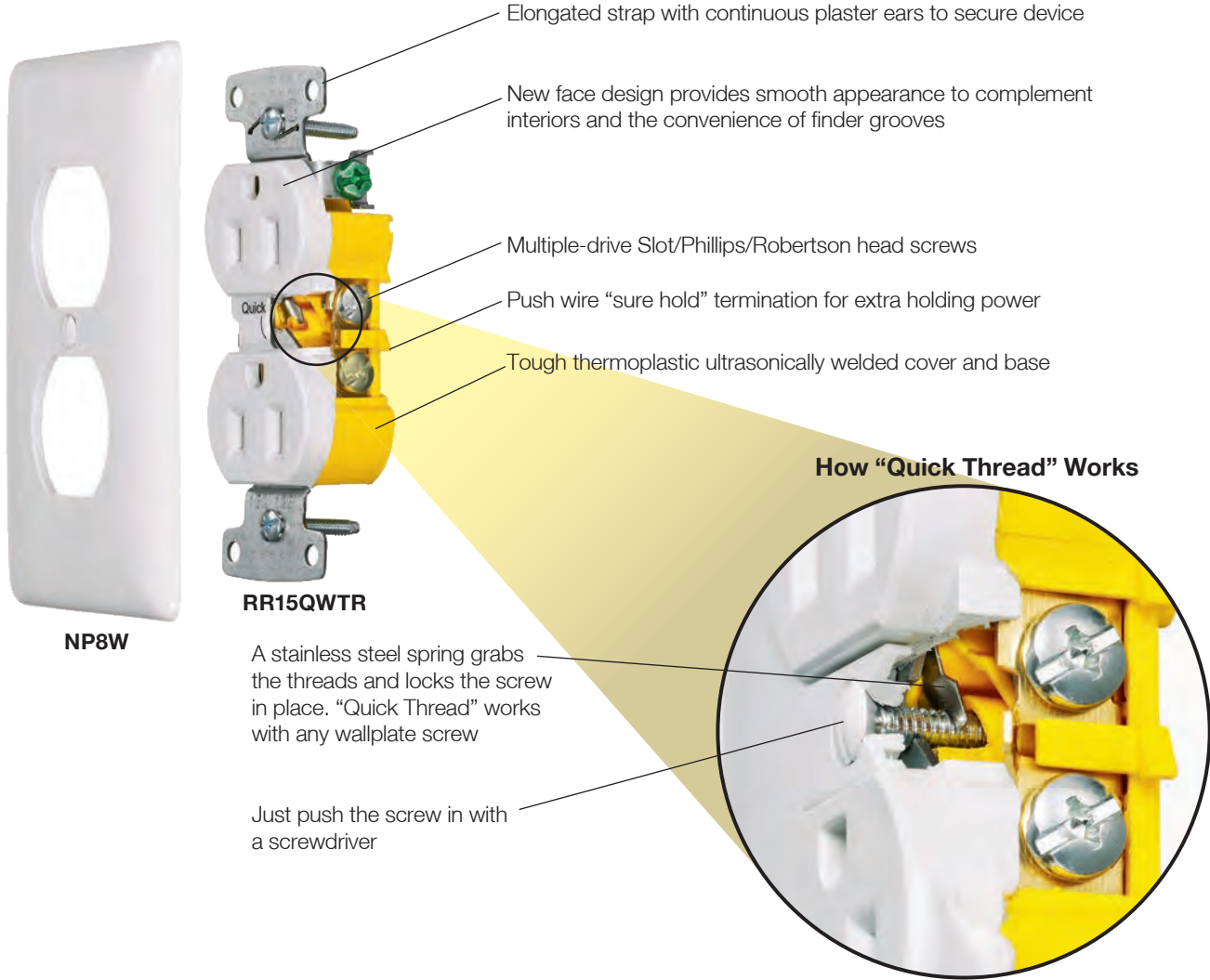

Duplex Quick Thread Receptacles, 2 Pole, 3 Wire



	 Tamper-Resistant, Quick Thread	 Tamper-Resistant, Quick Thread
Description	Tamper-Resistant, Quick Thread	Tamper-Resistant, Quick Thread
Termination	Self-Grounding, Push and Side Wire	Eight Push Wire Holes Only #14 AWG
Rating	15A 125V NEMA 5-15R	15A 125V NEMA 5-15R
Black	RR15QBKTR	RR15EQBKTR
Brown	RR15QTR	RR15EQTR
Ivory	RR15QITR	RR15EQITR
Light Almond	RR15QLATR	RR15EQLATR
White	RR15QWTR	RR15EQWTR

Note: See page Tech-10 for Tamper-Resistant description.