


15 and 20 Ampere, 125 Volts



15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

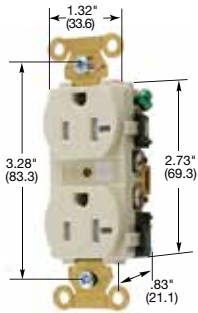


HBL5362ITR

HBL® Extra Heavy Duty Max Tamper-Resistant Receptacles

Duplex
Flush, nylon face, Tamper-Resistant, back and side wired.

Color	Catalog Number	Catalog Number
Black	HBL5262BKTR	HBL5362BKTR
Blue	HBL5262BLTR	HBL5362BLTR
Brown	HBL5262TR	HBL5362TR
Gray	HBL5262GYTR	HBL5362GYTR
Ivory	HBL5262ITR	HBL5362ITR
Light Almond	HBL5262LATR	HBL5362LATR
Red	HBL5262RTR	HBL5362RTR
White	HBL5262WTR	HBL5362WTR

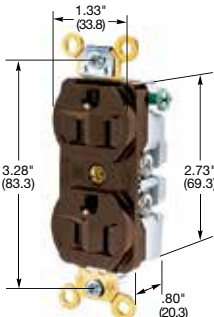


HBL5252

HBL® Extra Heavy Duty Max Compact Receptacles

Duplex
Flush, nylon face, back and side wired.

Color	Catalog Number	Catalog Number
Black	HBL5252BK	HBL5352BK
Blue	-	HBL5352BL
Brown	HBL5252	HBL5352
Gray	HBL5252GY	HBL5352GY
Ivory	HBL5252I	HBL5352I
Red	HBL5252R	HBL5352R
White	HBL5252W	HBL5352W

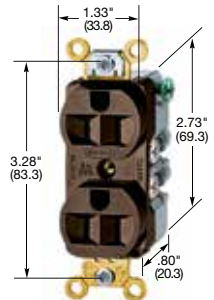

HBL5242

On a 4 in. (101.6) round cover.

Brown	HBL5253	-
Flush, nylon face, side wired only.	Brown HBL5242	HBL5342
	Gray HBL5242GY	HBL5342GY
	Ivory HBL5242I	HBL5342I
	White HBL5242W	HBL5342W

Ring terminal connection.

Brown	HBL5242RT	HBL5342RT
-------	------------------	------------------

Single

Flush, side wired only.

Brown	HBL5251	-
Ivory	HBL5251I	-
Panel mount 1.75 in. (44.5) centers.	Brown HBL5258	HBL5358
	Ivory HBL5258I	-

Style Line® Decorator*

Flush, nylon face, back and side wired.

Black	HBL2152BK	HBL2162BK
Brown	HBL2152	HBL2162
Gray	HBL2152GY	HBL2162GY
Ivory	HBL2152I	HBL2162I
White	HBL2152WA	HBL2162WA

Isolated ground^A.


Gray	-	IG2162GY
Orange	IG2152	IG2162

Note: ^ASee section N for additional information on isolated ground devices.


*Style Line Duplex devices are not Fed. Spec. Listed.

See page A-47 for accessories.

See section O for wallplates.

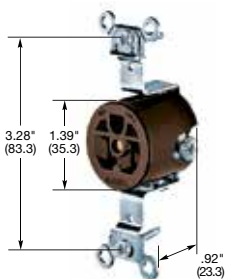

HBL5251

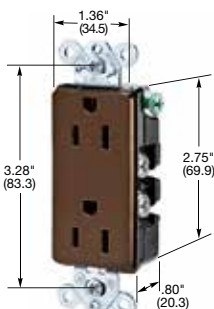

HBL2152

Dimensions in Inches (mm)