

**20 Amp, 347, 480, 600 and 125/250 Volts AC**  
**2 Pole, 3 Wire, Grounding and 3 Pole, 3 Wire, Non-Grounding**

**IP20**  
SUITABILITY



**HBL2341**

## Plugs


Description	Cord Dia.	Catalog Number			
Black and white nylon.	.360"-.930" (9-24)	<b>HBL3721</b>	<b>HBL2341</b>	<b>HBL2351</b>	-
Black and white nylon (Not shown).	.300"-1.050" (7.6-26.7)	-	-	-	<b>HBL2361</b>

Note: See page B-54 for accessories.

## Flanged Inlets

Description	Catalog Number			
Nylon casing, back wired.	<b>HBL3725</b>	<b>HBL2345</b>	<b>HBL2355</b>	<b>HBL2365</b>

Note: See page B-54 for accessories.

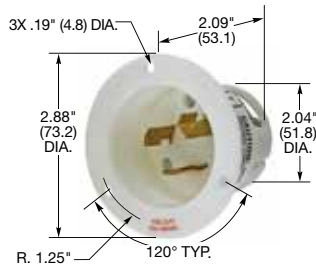

**HBL2345**

**IP20**  
SUITABILITY



## Connector Bodies

Description	Cord Dia.	Catalog Number			
Black and white nylon.	.360"-.930" (9-24)	<b>HBL3723</b>	<b>HBL2343</b>	<b>HBL2353</b>	-
Black and white nylon (Not shown).	.300"-1.050" (7.6-26.7)	-	-	-	<b>HBL2363</b>

Note: See page B-54 for accessories.




**HBL2343**

## Single Flush Receptacles

Description	Catalog Number			
Black nylon face, back and side wired.	<b>HBL3720</b>	<b>HBL2340</b>	<b>HBL2350</b>	<b>HBL2360</b>
Watertight Safety-Shroud®, gray Valox® housing and flange, back and side wired, (Not shown).	-	<b>HBL2340SW</b>	-	-
Isolated ground, orange nylon face, back and side wired.	-	<b>IG2340</b>	-	-

Note: See page B-54 for accessories.

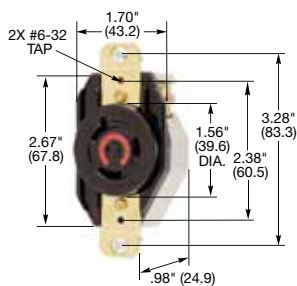

**HBL2340**

## Flanged Receptacles

Description	Catalog Number			
Nylon casing, back wired.	<b>HBL3726</b>	<b>HBL2346</b>	<b>HBL2356</b>	<b>HBL2366</b>

Note: See page B-54 for accessories.


See page B-71 for technical information.

See page B-41 for switched enclosure.

See page B-44 for Add-A-Shroud® kit. For use with connector bodies.

Only receptacles and plugs up to 480V AC are HP rated.

HP ratings are AC only.

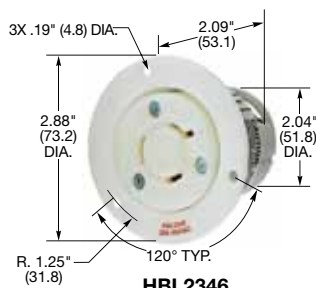

**HBL2346**

Dimensions in Inches (mm)

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.