 


Twist-Lock® Devices



**30 Amp, 125, 250 Volts and 277 Volts AC
2 Pole, 3 Wire, Grounding**



Connector Bodies

Watertight Safety-Shroud®

Description	Cord Dia.	IP66 SUITABILITY		UL Type 4x, 12
		Catalog Number	Catalog Number	
Black Valox® housing, white Valox® clamps.	.360"-.930" (9-24)	HBL2613SW	HBL2623SW	-
Reverse service, black Valox® housing, white Valox® clamps (use with HBL2615SWR), (Not shown).	.360"-.930" (9-24)	HBL2613SR	-	-

Insulgrip®

Description	Cord Dia.	IP20 SUITABILITY		
		Catalog Number	Catalog Number	Catalog Number
Black and white nylon.	.360"-.930" (9-24)	HBL2613	HBL2623	HBL2633
Heat stabilized, gray nylon, 220° F (104° C).	.360"-.930" (9-24)	HBL2613F	HBL2623F	-
Corrosion resistant, yellow nylon.	.360"-.930" (9-24)	HBL26CM13	HBL26CM23	-
All black nylon.	.360"-.930" (9-24)	HBL2613BK	HBL2623BK	-

Note: See page B-54 for accessories.

Valise®

Description	Cord Dia.	IP20 SUITABILITY		
		Catalog Number	Catalog Number	Catalog Number
Yellow nylon.	.590"-.930" (15.0-23.6)	HBL2613VY	HBL2623VY	-
Corrosion resistant, yellow nylon.	.590"-.930" (15.0-23.6)	HBL26CM13V	-	-
Black nylon.	.590"-.930" (15.0-23.6)	HBL2613VBK	HBL2623VBK	-
Cord clamps with removable inserts. All black nylon.	.360"-.930" (9-24)	-	HBL2623EBK	-

Note: See page B-55 for accessories.

Receptacles

Watertight Safety-Shroud®

Description	IP66 SUITABILITY		UL Type 4x, 12
	Catalog Number	Catalog Number	
Gray Valox® housing and flange, back wired.	HBL2610SW	HBL2620SW	-

Note: See page B-56 for accessories.

Safety-Shroud® Twist-Lock®

Description	IP20 SUITABILITY		
	Catalog Number	Catalog Number	Catalog Number
Gray Valox® angle housing, one gang, back wired.	HBL2610AR	HBL2620AR	-
Gray Valox® surface mounting, one gang, back wired.	HBL2610SR	HBL2620SR	-
Gray Valox® semi-flush, two gang, back wired.	HBL2610SR2	HBL2620SR2	-

Single Flush Receptacles

Description	IP20 SUITABILITY		
	Catalog Number	Catalog Number	Catalog Number
Black nylon face, back and side wired.	HBL2610	HBL2620	HBL2630
Black nylon face, spring terminals.	HBL2610ST	HBL2620ST	-
Blue nylon face, back and side wired.	HBL2610M6	HBL2620M6	-
Isolated ground, orange nylon face, back and side wired.	IG2610	IG2620	-
Corrosion resistant, yellow nylon face, back and side wired.	HBL26CM10	HBL26CM20	-
Ring terminal connection.	HBL2610RT	HBL2620RT	-

Note: See page B-54 for accessories.

Insulgrip® Flanged Receptacles

Description	Catalog Number		
	Nylon casing, back wired.	HBL2616	HBL2626
Heat stabilized, gray nylon, 220° F (104° C).	HBL2616F	HBL2626F	-

Note: See page B-54 for accessories.


Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.



HBL2613SW




HBL2623

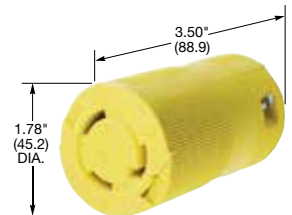

HBL2613VY



HBL2610SW

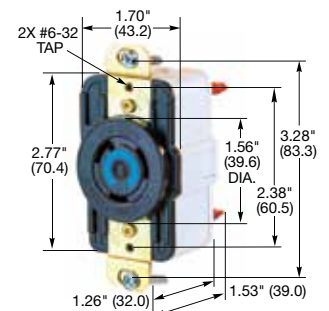

HBL2610ST



HBL2620SR

Dimensions in Inches (mm)