


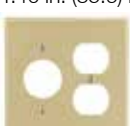
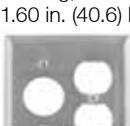





## Combination Wallplates, 2-Gang

Description	Color	Thermoplastic		Material	Metal Catalog Number
		Standard	Mid-Size		
 2-Gang, 1-Toggle, 1-Duplex	Brown	<b>P18</b>	-	Aluminum	①
	Gray	<b>P18GY</b>	<b>PJ18GY</b>	Brass	<b>SB18</b>
	Ivory	<b>P18I</b>	<b>PJ18I</b>	Brass Plated	-
	Light Almond	<b>P18LA</b>	<b>PJ18LA</b>	Chrome	<b>SCH18</b>
	Red	<b>P18R</b>	-	S/S 302/304	<b>SS18</b>
	White	<b>P18W</b>	<b>PJ18W</b>		
 2-Gang, 1-Duplex, 1-Decorator	Black	<b>P826BK</b>	<b>PJ826BK</b>	Aluminum	①
	Brown	<b>P826</b>	<b>PJ826</b>	Brass	<b>SB826</b>
	Gray	<b>P826GY</b>	<b>PJ826GY</b>	Brass Plated	①
	Ivory	<b>P826I</b>	<b>PJ826I</b>	Chrome	①
	Light Almond	<b>P826LA</b>	<b>PJ826LA</b>	S/S 302/304	<b>SS826</b>
	Red	<b>P826R</b>	-		
 2-Gang, 1-Toggle, 1-Decorator	Black	<b>P126BK</b>	-	Aluminum	①
	Brown	<b>P126</b>	<b>PJ126</b>	Brass	<b>SB126</b>
	Gray	<b>P126GY</b>	<b>PJ126GY</b>	Brass Plated	-
	Ivory	<b>P126I</b>	<b>PJ126I</b>	Chrome	①
	Light Almond	<b>P126LA</b>	<b>PJ126LA</b>	S/S 302/304	<b>SS126</b>
	Red	<b>P126R</b>	-		
 2-Gang, 1-Toggle, 1-Decorator	White	<b>P126W</b>	<b>PJ126W</b>		
	Ivory	<b>P78I</b>	-	Aluminum	①
	White	<b>P78W</b>	-	Brass	①
				Brass Plated	①
				Chrome	①
				S/S 302/304	<b>SS78</b>
 2-Gang, 1-Single Receptacle 1.40 in. (35.6) Hole, 1-Duplex				Aluminum	①
				Brass	①
				Brass Plated	①
				Chrome	①
				S/S 302/304	<b>SS8720</b>
 2-Gang, 1-Single Receptacle 1.60 in. (40.6) Hole, 1-Duplex				Aluminum	①
				Brass	①
				Brass Plated	①
				Chrome	①
				S/S 302/304	<b>SS8720</b>
 2-Gang, 1-Toggle, 1-Blank Box Mount	Brown	-	<b>PJ113</b>	Aluminum	①
	Gray	<b>P113GY</b>	-	Brass	①
	Ivory	<b>P113I</b>	<b>PJ113I</b>	Brass Plated	①
	Light Almond	<b>P113LA</b>	-	Chrome	①
	White	<b>P113W</b>	<b>PJ113W</b>	S/S 302/304	<b>SS113</b>
 2-Gang, 1-Toggle, 1-Blank Strap Mount				Aluminum	①
				Brass	①
				Brass Plated	①
				Chrome	①
				S/S 302/304	<b>SS114</b>
 2-Gang, 1-Blank, 1-Decorator Box Mount	Black	<b>P1326BK</b>	-	Aluminum	①
	Gray	<b>P1326GY</b>	-	Brass	①
	Ivory	<b>P1326I</b>	<b>PJ1326I</b>	Brass Plated	①
	Light Almond	<b>P1326LA</b>	<b>PJ1326LA</b>	Chrome	①
	White	<b>P1326W</b>	<b>PJ1326W</b>	S/S 302/304	<b>SS1426*</b>

Note: Thermoplastic wallplates feature pre-inserted captive screws for faster assembly in single gang configurations.

① Available as a custom wallplate, see pages O-32 to O-34. Consult custom wallplates section for additional openings and combinations.

\*Strap Mount.

Dimensions in Inches (mm)