

Features and Benefits

Weatherproof Non-Metallic While-In-Use Covers


The NEMA 3R Rated EXTRA DUTY® Metallic and Non-metallic While-in-Use Covers offer weather protection for outlets when they are in use.

- Patented keyhole mounting system allows installation in under a minute
- Pre-configured for GFCI with patented technology for alternate devices
- Lockable tab for OSHA compliance
- Sealed-in-place gasket
- High-impact polycarbonate construction provides maximum durability
- Each box contains three or six adapters to make a variety of configurations (16 or 55)




Non-Metallic While-In-Use Covers


Description	Dimensions Height x Width x Depth	Standard	EXTRA DUTY®
Standard 1-gang box with clear tinted cover, for horizontal or vertical mounting; 16-in-1 configurations.	1.16 Product Variations 5.90" X 4.18" X 2.75" (149.8 X 106.1 X 69.9)	RW57300	RW58300
Extra deep 1-gang box with clear tinted cover, for horizontal or vertical mounting; 16-in-1 configurations.	1.16 Product Variations 5.92" X 4.20" X 4.75" (150.4 X 106.7 X 120.7)	RW57350	RW58350
Standard 2-gang box, clear tinted cover, for vertical mounting only; 55-in-1 configurations.	1.55 Product Variations 5.54" X 5.43" X 2.75" (140.7 X 138.0 X 69.9)	RW57750	RW58750

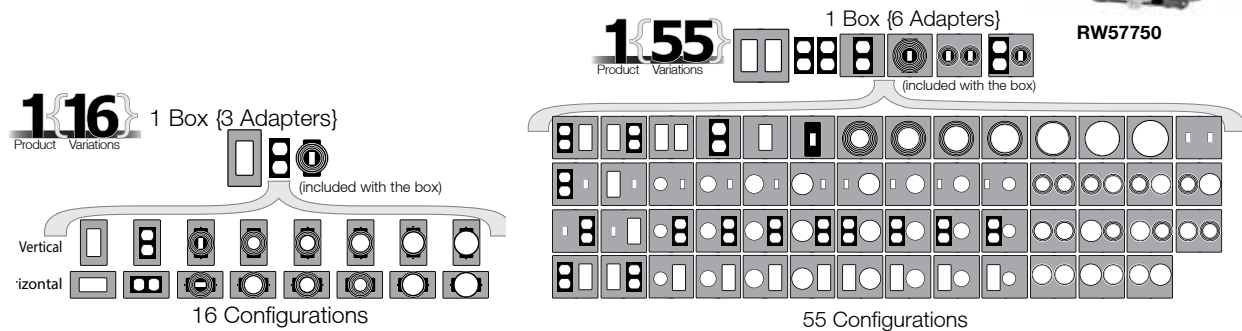


Non-Metallic Cover Dimensions

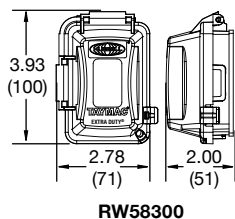

RW58300

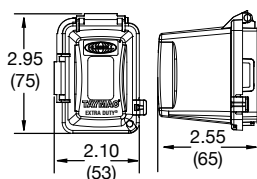

RW58350

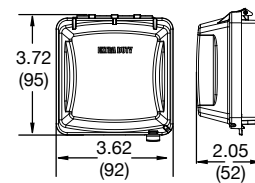

RW58750

Dimensions in Inches (mm)