

Light Duty Grips

Light Duty Grips are made of galvanized steel in a single weave construction. They feature a flexible eye for easy attachment to a pulling line.


IMPORTANT:

Read all breaking strength, safety and technical data relating to this product.

Refer to pages X-17 and X-18.

Benefits

- Perfect tools for light pulling jobs
- Installs easily on cable
- Strong galvanized steel construction

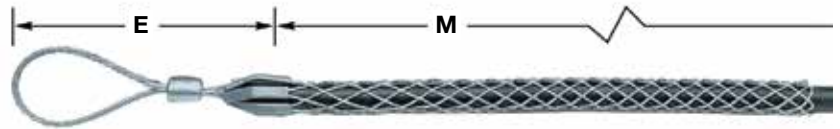

Light Duty Grips


Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
Short					
.50"- .62" (1.27-1.57)	2,800	560	5" (12.70)	11" (27.94)	03303001
.63"- .74" (1.60-1.88)	2,800	560	5" (12.70)	11" (27.94)	03303002
.75"- .99" (1.90-2.51)	4,000	800	6" (15.24)	12" (30.48)	03303003
1.00"-1.24" (2.54-3.15)	5,300	1,060	7" (17.78)	13" (33.02)	03303004
1.25"-1.49" (3.17-3.78)	5,300	1,060	7" (17.78)	14" (35.56)	03303005
1.50"-1.74" (3.81-4.42)	6,800	1,360	8" (20.32)	15" (38.10)	03303006
1.75"-1.99" (4.44-5.05)	8,500	1,700	9" (22.86)	17" (43.18)	03303007
2.00"-2.49" (5.08-6.32)	8,500	1,700	9" (22.86)	18" (45.72)	03303008
Standard					
.50"- .62" (1.27-1.57)	2,800	560	5" (12.70)	16" (40.64)	03303010
.63"- .74" (1.60-1.88)	2,800	560	5" (12.70)	16" (40.64)	03303011
.75"- .99" (1.90-2.51)	4,000	800	6" (15.24)	20" (50.80)	03303012
1.00"-1.24" (2.54-3.15)	6,800	1,360	7" (17.78)	20" (50.80)	03303013
1.25"-1.49" (3.17-3.78)	6,800	1,360	7" (17.78)	21" (53.34)	03303015
1.50"-1.99" (3.81-5.05)	6,800	1,360	8" (20.32)	23" (58.42)	03303016
2.00"-2.49" (5.08-6.32)	8,500	1,700	9" (22.86)	25" (63.50)	03303017
2.50"-2.99" (6.35-7.59)	10,600	2,120	9" (22.86)	27" (68.58)	03303018
3.00"-3.49" (7.62-8.86)	14,700	2,940	10" (25.40)	30" (76.20)	03303019
3.50"-3.99" (8.89-10.13)	14,700	2,940	10" (25.40)	32" (81.28)	03303029

Junior Pulling Grips

Junior Pulling Grips feature a strong galvanized steel, single weave mesh. A flexible eye easily attaches to a pulling line, snake or fish tape.

Benefits

- Installs easily over building wire
- Strong secure grip
- Reusable
- Pulls single cable or cable bundles

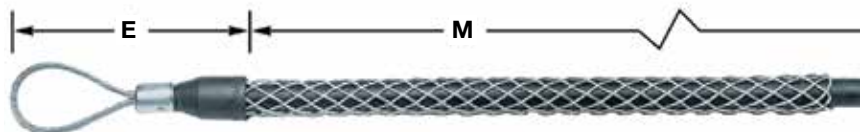

Junior Pulling Grips

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Model	Catalog Number
.19"- .24" (.48-.61)	400	80	3¼" (8.25)	4¼" (10.79)	J19	03305011*
.25"- .37" (.63-.94)	450	90	3¼" (8.25)	4¼" (10.79)	J25	03305001
.38"- .49" (.97-1.24)	900	180	3¾" (9.52)	7" (17.78)	J37	03305002
.50"- .62" (1.27-1.57)	1,300	260	4¼" (10.79)	8½" (21.59)	J50	03305003
.63"- .74" (1.60-1.88)	1,950	390	5" (12.70)	10" (25.40)	J62	03305004
.75"- .99" (1.90-2.51)	2,800	560	5¾" (14.60)	10" (25.40)	J75	03305005
1.00"-1.24" (2.54-3.15)	3,900	780	6½" (16.51)	11½" (29.21)	J100	03305006
Junior Grip Kit contains 6 grips, one of each size above, except 03305011.						033051114

Note: E- Eye length. M-Mesh length at nominal diameter.

*Not included in Junior Grip Kit, 033051114.

See page X-18 for multiple cables in a single pulling grip.

Dimensions in Inches (mm)