

Hubbellock® Devices
 60A, 600V AC, 3 Pole, 4 Wire Grounding
 Hubbellock® Plug

HUBBELL

Features

- Molded-in male contacts are resistant to damage and provide a consistently positive connection
- Insulated, color coded metallic housing enhances safety and abuse resistance
- Box terminals in conjunction with stainless steel terminal screws provide maximum termination strength and dependability

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Black phenolic interior with yellow thermoplastic sleeve over steel housing	.920"-1.450"(23.36-36.83)	783585017327	HBL26419

Listings

Listed to UL Standard
 Certified to CSA Standard

Specifications

Device Color	Black/White
Housing	Nylon
Cord Clamp Material	PET
Plug Housing	Thermoset
Contacts	Brass
Terminal Screws	Zinc plated steel
Assembly Screws	Stainless Steel

Performance

Electrical


Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage Withstand	2,000V minimum

Mechanical

Terminal Accommodation	#8 AWG - #4 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498

Environmental

Flammability	HB or better
Moisture Resistance	IP30 Suitability
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

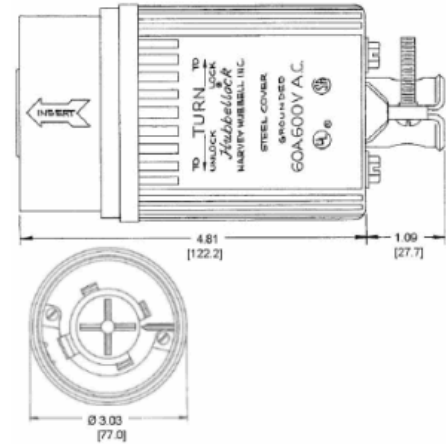

Accessories

Connector	HBL26418
Long Single Receptacle	HBL26410
Short Single Receptacle	HBL26420
Flanged Receptacle	HBL26421

Resources

Customer Use Drawing
 eCatalog